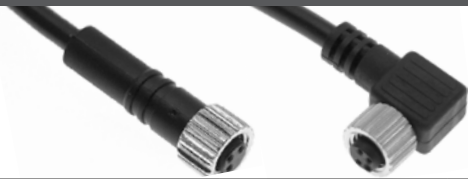


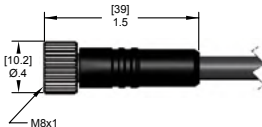
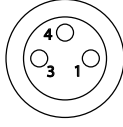
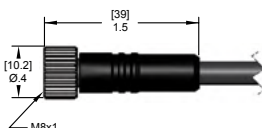
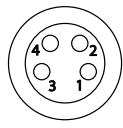
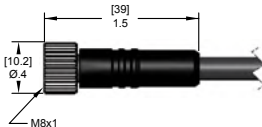
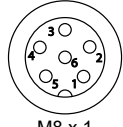
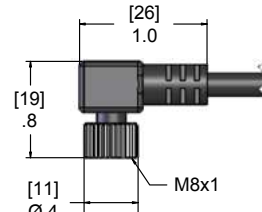
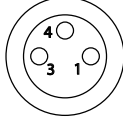
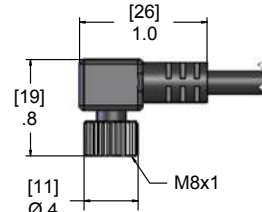
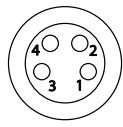


# NAN (M8) Series Thread-On Cordsets

3, 4 & 6 Conductor NAN Series Cordsets, 24/26AWG

Straight/ Right Angle Female Cordsets | Thread-On Style | 60 Volt, 3 amps | IP67 Rating



Thread-On Style: Female Straight Plugs					
Connector Body Style	Part Number	Cables	Features	Color Code	Faceview
	NAN-T-3FP-**	Black PVC AWM <b>3 X 24 AWG</b> 60V, 3A -40°C to +70°C 4.5mm OD	Industry Standard PVC	1. Brown 2. Not Used 3. Blue 4. Black	 M8 x 1
	NANP-T-3FP-**	Black PUR AWM <b>3 X 24 AWG</b> 60V, 3A -40°C to +80°C 4.5mm OD	Oil and Cutting Fluid Resistant Cut Resistant PUR		
	NAN-T-4FP-**	Black PVC AWM <b>4 X 24 AWG</b> 60V, 3A -40°C to +70°C 4.5mm OD	Industry Standard PVC	1. Brown 2. White 3. Blue 4. Black	 M8 x 1
	NANP-T-4FP-**	Black PUR AWM <b>4 X 24 AWG</b> 60V, 3A -40°C to +80°C 4.5mm OD	Oil and Cutting Fluid Resistant Cut Resistant PUR		
	NAN-T-6FP-**	Black PVC AWM <b>6 X 26 AWG</b> 60V, 3A -40°C to +105°C 4.5mm OD	Industry Standard PVC	1. Brown 2. White 3. Blue 4. Black 5. Gray 6. Pink	 M8 x 1
Thread-On Style: Female Right Angle Plugs					
	NAN-T-3FP-**-R	Black PVC AWM <b>3 X 24 AWG</b> 60V, 3A -40°C to +70°C 4.5mm OD	Industry Standard PVC	1. Brown 2. Not Used 3. Blue 4. Black	 M8 x 1
	NANP-T-3FP-**-R	Black PUR AWM <b>3 X 24 AWG</b> 60V, 3A -40°C to +80°C 4.5mm OD	Oil and Cutting Fluid Resistant Cut Resistant PUR		
	NAN-T-4FP-**-R	Black PVC AWM <b>4 X 24 AWG</b> 60V, 3A -40°C to +70°C 4.5mm OD	Industry Standard PVC	1. Brown 2. White 3. Blue 4. Black	 M8 x 1
	NANP-T-4FP-**-R	Black PUR AWM <b>4 X 24 AWG</b> 60V, 3A -40°C to +80°C 4.5mm OD	Oil and Cutting Fluid Resistant Cut Resistant PUR		

\*\* Lengths in meters. Standard cable lengths are 1, 2, 4, 5, 6, 10 & 15 meters. Consult factory for other lengths.

Standard coupling nut is nickel plated brass, for stainless steel coupling nut add a "SS" suffix. (e.g. NAN-T-4FP-1M becomes NAN-T-4FP-1M-SS)