

Search This Product Catalogue


By Keyword

- Electrical Products
 - Product Catalogue for Electrical Products
 - 3M™ Diagnostic and Detection Products
 - 3M™ Fire Protection Products
 - 3M™ Safety and Protection Products
 - Aerosols, Sprays and Coatings
 - Insulating, Jacketing and Repair
 - Low Voltage Splicing (0-1000V)
 - Medium Voltage Splicing and Terminating (5-46kV)
 - Moisture Sealing and Corrosion Protection
 - New Products
 - Wire Connecting
 - Wire Management

[Product Catalogue for Electrical Products > Wire Connecting . . . 3M™ Scotchlok™ Ring Tongues Vinyl Insulated Brazed Seam > 3M™ Scotchlok™ Ring Tongues Vinyl Insulated Brazed Seam, 22-18 AWG >](#)

3M™ Scotchlok™ Ring Tongue, Vinyl Insulated Brazed Seam MV18-8R/LK, Stud Size 8

[Printer-friendly format](#)

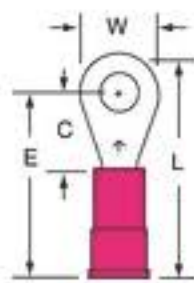

[\[click to enlarge\]](#)

This terminal has a wire range of 22-18 AWG and a stud size of 8. It comes in quantities of 1000 per case.

3M Order Code : 80-6100-3519-0
Bar Code : 0 00 54007 01053 1

Additional Information

A ring is the standard style of tongue. The safest and most reliable; it cannot be removed unless mounting screw is removed.

Learn More . . .

[Packaging Data](#)

Email [3M™ Wire Terminals, 2013 Product Catalog - Catalog \(PDF 17.1 MB\)](#)

Email [Ring Tongues - Vinyl Insulated Brazed Seam 22-18 AWG - Product Selection Guide \(PDF 28.6 K\)](#)

Email [Scotchlok Terminals MV18-2R/S THRU MV10-12R - Data Sheet \(PDF 24.2 K\)](#)

Email [Terminal Stud Size Chart - Product Selection Guide \(PDF 14.9 K\)](#)

Please Note:

Adobe® Acrobat® Reader is required to view PDF documents.



Characteristics

Agency Approvals	UL and CSA
Barrel Inside Diameter	0.07 Inch
Barrel Length	0.25 Inch
Barrel Style	Brazed
Brand	Scotchlok
Clearance ©	0.33 Inch
Conductor Sizes	22 - 18 AWG
CSA File Number	LR22190
Dimension E	0.78 Inch
Insulation Material	Vinyl
Length (L)	0.93 Inch
Maximum Insulation Outer Diameter	0.145 Inch
Packaging	1000 per bulk box
RoHS 2011/65/EU Compliant	Yes
Stud Size	8
Terminal Style	Standard
Terminal Type	Ring
Thickness	0.03 Inch
UL File Number	E23438
Width (W)	0.31 Inch