

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0002065108](#)
Status: **Active**
Overview: [standard_062](#)
Description: 1.57mm Diameter, Standard .062" Pin and Socket Crimp Terminal, Female, with Selective Gold (Au) Plated Brass Contact, 18-24 AWG, Reel

Documents:
[Drawing \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Crimp Terminals
Series	1561
Application	Power
Crimp Quality Equipment	Yes
Overview	standard_062
Product Name	Standard .062"

Physical


Gender	Female
Material - Metal	Brass
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Packaging Type	Reel
Plating min - Mating	0.762µm
Plating min - Termination	2.540µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.52-3.05mm
Wire Size AWG	18, 20, 22, 24
Wire Size mm²	N/A

Material Info

Old Part Number 1561-(P563)

Reference - Drawing Numbers

Sales Drawing SD-1561-*

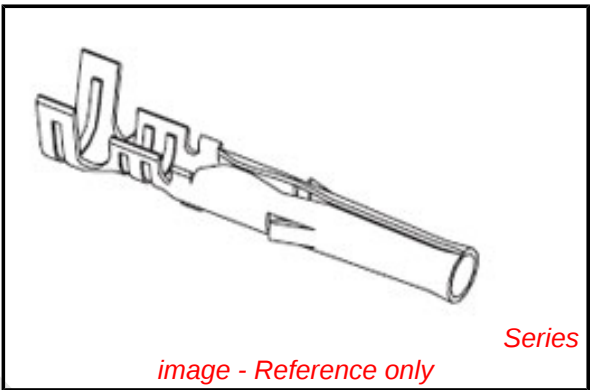

EU RoHS

**ELV and RoHS
Compliant**

REACH SVHC

Not Reviewed

Low-Halogen Status

Low-Halogen

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

[1561Series](#)

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
Mini-Mac™ Applicator	0011182017
Hand Crimp Tool for Standard 1.57mm Pin and Socket Crimp Terminals, 18-24 AWG	0638191300
Mini-Mac™ Applicator	0638914000
Hand Crimper - DISTRIBUTION ONLY	0638111000
Manual Extraction Tool	0011030002

Terminator Die	<u>0011402004</u>
Japan	
Description	Product #
Hand Insertion Tool	<u>0011020001</u>

This document was generated on 01/26/2012

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

onlinecomponents.com