

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0009505155
Status: Obsolete
Description: 3.96mm (.156") Pitch KK® Crimp Housing, Edge Card Connector, Double-Sided, Surface Mount, 30 Circuits

Documents:
[Drawing \(PDF\)](#)

Agency Certification

UL E29179

General

Product Family Edge Card Connectors
Series 4338
Comments 15 Dual Circuit Pairs
Component Type Edgecard to Wire
Product Name Edge Card, KK®

Physical

(p)ower-(s)ignal Configuration 30s - 0p
Circuits (Loaded) 30
Circuits (maximum) 30
Color - Resin Black
Durability (mating cycles max) 25
Entry Angle Vertical (Top Entry)
Flammability 94V-0
Keying to Mating Part N/A
Material - Plating Mating n/a
Material - Resin Polyester
PCB Retention None
Packaging Type Bag
Pitch - Mating Interface 3.96mm (.156")
Temperature Range - Operating 0°C to +75°C
Termination Interface: Style N/A

Electrical


Current - Maximum per Contact 5A
Voltage - Maximum 250V

Material Info

Old Part Number 4338151

Reference - Drawing Numbers

Product Specification PS-09-50

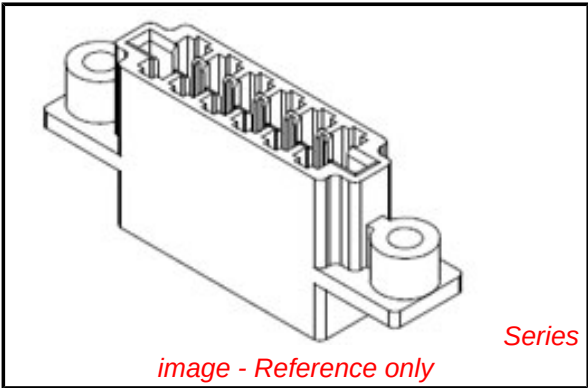

EU RoHS

**ELV and RoHS
Compliant**
REACH SVHC
Contains SVHC: No
Low-Halogen Status
Not Low-Halogen

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of
Compliance, [click here](#)

Please visit the [Contact Us](#) section for any
non-product compliance questions.

Search Parts in this Series
4338Series

Mates With
PCB, 1.6mm (0.62") max. thickness

Use With
4366 , 4573 , 4574 Terminals . 11030003
Extraction Tool