

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0010015042](#)
Status: **Planned for Obsolescence**
Overview: [kk](#)
Description: 5.08mm (.200") Pitch KK® Crimp Terminal Housing, 4 Circuits

Documents:

3D Model	Product Specification PS-5058-002 (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-5058-001 (PDF)	

Agency Certification

CSA	LR19980
TUV	R72090224
UL	E29179

General

Product Family	Crimp Housings
Series	5058
Application	Power
Overview	kk
Product Name	KK®

Physical


Circuits (maximum)	4
Color - Resin	Natural
Flammability	94V-2
Gender	Female
Glow-Wire Compliant	No
Material - Resin	Nylon
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	5.08mm (.200")
Stackable	No
Temperature Range - Operating	-40°C to +105°C

Material Info

Old Part Number	5058-04
-----------------	---------

Reference - Drawing Numbers

Product Specification	PS-5058-001, PS-5058-002, RPS-5058-001
Sales Drawing	SD-5058-001

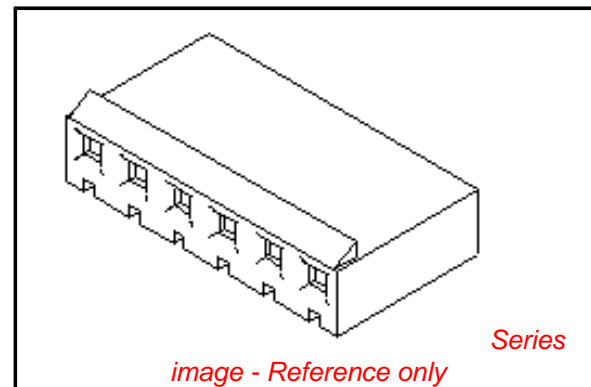

EU RoHS

**ELV and RoHS
Compliant**

REACH SVHC

**Contains SVHC: No
Low-Halogen Status
Not Reviewed**

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

[5058Series](#)

Mates With

[5279](#) , [5280](#) , [5281](#) , [5282](#) , [5283](#)

Use With

[5168](#) Cat Ear Crimp Terminals for 22-28 AWG, [2478](#) Crimp Terminals for 18-24 AWG, [2578](#) Crimp Terminals for 22-26 AWG, [5167](#)