

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0039000372](#)
Status: **Active**
Description: MINI KK CRIMP RECEPT 2759T

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family Crimp Terminals
 Series [2759](#)
 Crimp Quality Equipment Yes
 Product Name KK 254
 UPC 800754317092

Physical


Net Weight 0.040/g

Material Info

Engineering Number 2759T

Reference - Drawing Numbers

Sales Drawing SD-2759X-001

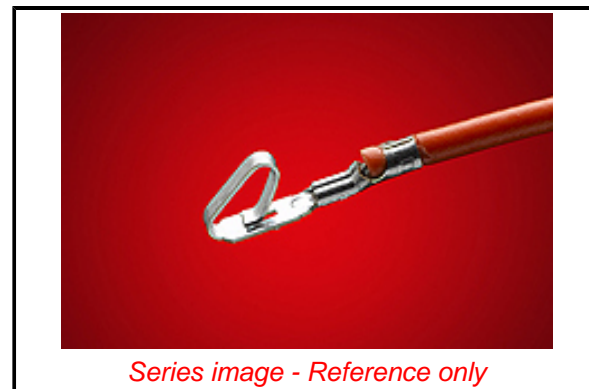

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 ED/71/2019 (16 July
 2019)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[2759 Series](#)

Application Tooling | [FAQ](#)

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
Extraction Tool	11030022
Insertion Tool	638120000
Mini-Mac Applicator for Insulation OD 1.09-1.57mm, 22-30 AWG Wire	638882000
Mini-Mac Applicator for Insulation OD 0.96-1.20mm, 22-30 AWG Wire	638882100

Japan

Description	Product #
-------------	-----------

Applicator for M211A 11260107
Bench Press, 22-28
AWG Wire

This document was generated on 10/09/2019

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION