

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0039010073](#)  
**Status:** **Planned for Obsolescence**  
**Description:** 2.50mm (.098") Pitch Wire-to-Board Receptacle Housing, Low Profile, 7 Circuits

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Product Specification PS-5480-001 \(PDF\)](#)

**Agency Certification**

CSA LR19980  
 UL E29179

**General**

Product Family Crimp Housings  
 Series [5480](#)  
 Application Signal  
 Product Name N/A

**Physical**


Circuits (maximum) 7  
 Color - Resin Natural  
 Flammability 94V-0  
 Gender Female  
 Glow-Wire Compliant No  
 Material - Resin Polyester  
 Number of Rows 1  
 Packaging Type Bag  
 Panel Mount No  
 Pitch - Mating Interface 2.50mm (.098")  
 Stackable No  
 Temperature Range - Operating -40°C to +105°C

**Material Info**

Old Part Number 5480-07

**Reference - Drawing Numbers**

Product Specification PS-5480-001, RPS-5480-001, RPS-5480-002, RPS-5480-003, RPS-5483-001, RPS-5483-002  
 Sales Drawing SD-5480-N

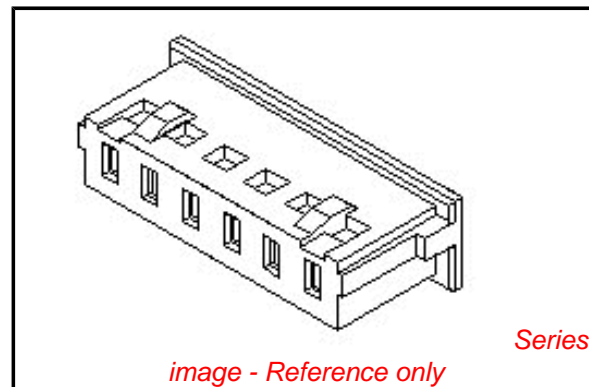

*image - Reference only*

**EU RoHS**

**ELV and RoHS Compliant**  
**REACH SVHC**  
**Contains SVHC: No**  
**Low-Halogen Status**  
**Not Low-Halogen**

**China RoHS**



**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

**Search Parts in this Series**

5480Series

**Mates With**

5483 , 5484

**Use With**

5479

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**