

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0039010153](#)
Status: **Planned for Obsolescence**
Description: 2.50mm (.098") Pitch Wire-to-Board Receptacle Housing, Low Profile, 15 Circuits

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-5480-001 \(PDF\)](#)

Agency Certification

CSA LR19980
 UL E29179

General

Product Family Crimp Housings
 Series [5480](#)
 Application Signal
 Product Name N/A

Physical

Circuits (maximum) 15
 Color - Resin Natural
 Flammability 94V-0
 Gender Female
 Glow-Wire Compliant No
 Material - Resin Polyester
 Number of Rows 1
 Packaging Type Bag
 Panel Mount No
 Pitch - Mating Interface 2.50mm (.098")
 Stackable No
 Temperature Range - Operating -40°C to +105°C

Material Info

Old Part Number 5480-15

Reference - Drawing Numbers

Product Specification PS-5480-001, RPS-5480-001, RPS-5480-002,
 RPS-5480-003, RPS-5483-001, RPS-5483-002
 Sales Drawing SD-5480-N

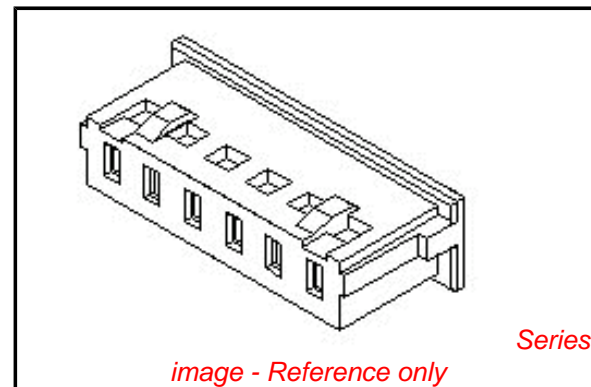


image - Reference only

EU RoHS

**ELV and RoHS
 Compliant**
**REACH SVHC
 Contains SVHC: No**
**Low-Halogen Status
 Not Low-Halogen**

China RoHS



**Need more information on product
 environmental compliance?**

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of
 Compliance, [click here](#)

Please visit the [Contact Us](#) section for any
 non-product compliance questions.

Search Parts in this Series

5480Series

Mates With

5483 , 5484

Use With

5479