

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0151350502](#)  
**Status:** **Active**  
**Overview:** CLIK-Mate Wire-to-Board Connectors  
**Description:** CLIK-Mate-to-CLIK-Mate Off-the-Shelf (OTS) Cable Assembly, Single Row, 150.00mm Length, 5 Circuits, Beige

**Documents:**

[Drawing \(PDF\)](#) [Product Literature \(PDF\)](#)  
[RoHS Certificate of Compliance \(PDF\)](#)

**General**

|                             |  |
|-----------------------------|--|
| Product Family              | Cable Assemblies                                   |
| Series                      | <a href="#">15135</a>                              |
| Application                 | Signal, Wire-to-Board                              |
| Assembly Configuration      | Dual Ended Connectors                              |
| Connector to Connector      | CLIK-Mate-to-CLIK-Mate                             |
| Overmolded                  | No   |
| Overview                    | <a href="#">CLIK-Mate Wire-to-Board Connectors</a> |
| Product Literature Order No | 987651-6143  |
| Product Name                | CLIK-Mate  |
| Type                        | Discrete Wire Assembly                             |
| UPC                         | 191128160179                                       |

**Physical**

|                                |                      |
|--------------------------------|----------------------|
| Cable Length                   | 150.00mm             |
| Circuits (Loaded)              | 5                    |
| Color - Resin                  | Beige                |
| Gender                         | Male-Male            |
| Lock to Mating Part            | Yes                  |
| Material - Metal               | Copper Alloy         |
| Material - Plating Mating      | Tin                  |
| Material - Plating Termination | Tin                  |
| Material - Resin               | PBT                  |
| Net Weight                     | 2.232/g              |
| Number of Rows                 | 1                    |
| Packaging Type                 | Bag                  |
| Pitch - Mating Interface       | 1.50mm               |
| Plating min - Mating           | 0.406µm              |
| Plating min - Termination      | 0.406µm              |
| Single Ended                   | No                   |
| Termination Interface: Style   | Crimp or Compression |
| Wire Insulation Diameter       | 1.10mm               |
| Wire Size AWG                  | 24                   |
| Wire/Cable Type                | UL 1061              |


**Electrical**

|                               |                  |
|-------------------------------|------------------|
| Current - Maximum per Contact | 1.5A             |
| Voltage - Maximum             | 100V AC (RMS)/DC |

**Material Info**

**Reference - Drawing Numbers**

|               |                |
|---------------|----------------|
| Sales Drawing | 2012341676-000 |
|---------------|----------------|

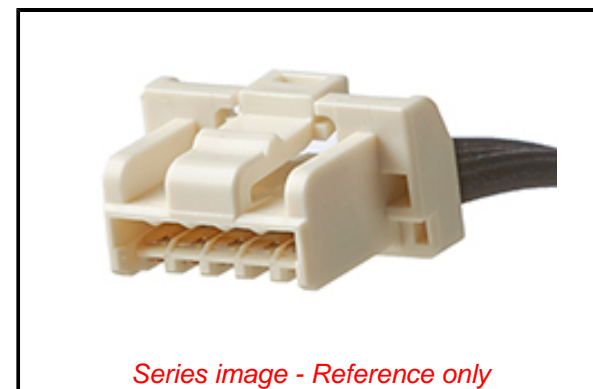

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
ED/71/2019 (16 July  
2019)

**Halogen-Free**

**Status**

**Not Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[15135 Series](#)

**Mates With**

[503395](#) Bottom-Entry Receptacle . [503175](#)  
Right Angle, Through Hole Receptacle .  
[502585](#) Right Angle, Surface Mount  
Receptacle <br> [503159](#) Vertical, Through  
Hole Receptacle <br> [502584](#) , [505405](#)  
Vertical, Surface Mount Receptacle