

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0191930289](#)
Status: **Active - Custom**
Description: VersaKrimp™ Ring Tongue Terminal for 4 AWG Wire

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-19902-013 \(PDF\)](#)

Agency Certification

CSA	LR18689
UL	E32244

General

Product Family	Ring and Spade Terminals
Series	19193
Crimp Quality Equipment	Yes
Mil-Spec	N/A
Product Name	VersaKrimp™
Type	Ring

Physical

Barrel Type	Closed - Brazed
Insulation	None
Material - Plating Mating	Tin
Packaging Type	Bag
Plating min - Mating	2.540µm (100µ")
Plating min - Termination	2.540µm (100µ")
Stud Size	3/4" (M18)
Termination Interface: Style	Crimp or Compression
Wire Size AWG	4

Material Info

Old Part Number	F-370-34
-----------------	----------

Reference - Drawing Numbers

Product Specification	PS-19902-013
Sales Drawing	SD-19193-006

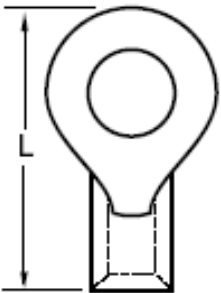


image - Reference only

Series

EU RoHS
ELV and RoHS
Compliant
REACH SVHC
Contains SVHC: No
Low-Halogen Status
Not Reviewed

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
[19193Series](#)

Application Tooling | FAQ
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
Manual tool for Crimping non-insulated 8AWG thru 4/0 Terminals	0192940008
Manual Putt Pump Hydraulic System, Die set required	0192860117
Die Set (large) for the HHLS Hydralic Crimper	0192900007
Putt Pump Dieless Head System	0192860065
Hand Crimp Tool	0640013900

This document was generated on 03/02/2011

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION