

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0350369802](#)
Status: **Active**
Description: .250mm Fuse Terminal, 0.85mm² - 2.50mm²

Documents:

[Drawing \(PDF\)](#) [Packaging Specification PK-35036-001-001 \(PDF\)](#)
[Product Specification PS-35036-002-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Crimp Terminals
Series	35036
Application	Power, Wire-to-Component
Comments	Box Type, Box Type
Crimp Quality Equipment	Yes
Product Name	N/A
UPC	800753238848

Physical

Durability (mating cycles max)	10
Gender	Female
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	0.760/g
Packaging Type	Reel
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	2.20-3.10mm
Wire Size AWG	14, 16, 18
Wire Size mm ²	0.85-2.50


Electrical

Current - Maximum per Contact	10.0A, 18.0A
Voltage - Maximum	3V

Material Info

Reference - Drawing Numbers

Crimp Specification	CS-35036-001-001
Packaging Specification	PK-35036-001-001
Product Specification	PS-35036-002-001
Sales Drawing	SD-35036-001

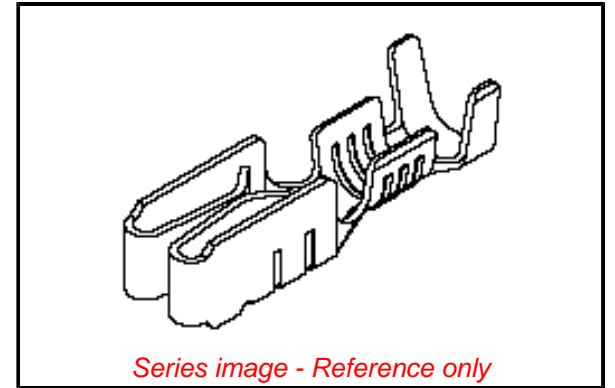

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/71/2019 (16 July
2019)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Compliant

Not Contained

Search Parts in this Series
[35036 Series](#)