

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0357303100**
Status: **Contact Molex**
Description: 3.96mm (.156") Diameter Pin Terminal, Brass, 0.40mm (.016") Thickness, Wire Range 14-20 AWG (2.00-0.52mm²), Unplated

Documents:

[Drawing \(PDF\)](#) [Packaging Specification PK-35730-002 \(PDF\)](#)
[Product Specification PS-35730-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Crimp Terminals
Series	<u>35730</u>
Application	Power
Crimp Quality Equipment	Yes
Product Name	N/A


Physical

Gender	Female
Material - Metal	Brass
Material - Plating Mating	Unplated
Packaging Type	Reel
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	3.50mm (.138") max.
Wire Size AWG	14, 16, 18, 20
Wire Size mm ²	N/A

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-35730-002
Product Specification	PS-35730-001
Sales Drawing	SD-35730-31*0

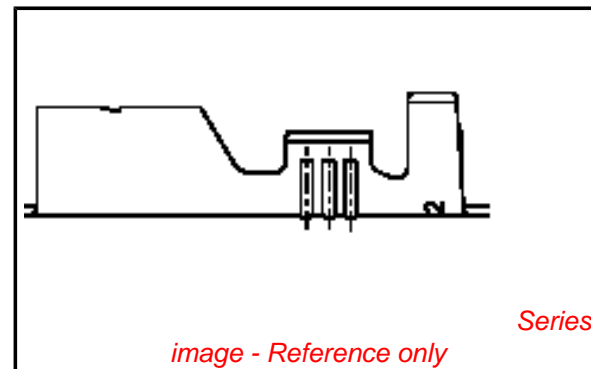

EU RoHS

**ELV and RoHS
Compliant
REACH SVHC
Contains SVHC: No
Low-Halogen Status
Low-Halogen**

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
35730Series

Mates With
35730-30*0