

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0391702115](#)  
**Status:** **Obsolete**  
**Description:** Interface Module, Male D-Sub Connector to Eurostyle™ Pluggable 15 Circuits, with DIN Rail Adapter Unit

**Documents:**  
[Drawing \(PDF\)](#)

**General**

Product Family	Terminal Blocks
Series	<a href="#">39170</a>
Application	Wire-to-Wire
Comments	Male D-Sub
Component Type	One Piece
Product Name	D-Sub, Eurostyle™ Pluggable
Type	Interface Module

**Physical**

Circuits (Loaded)	15
Entry Angle	180° Angle
Lock to Mating Part	None
Number of Rows	2
Orientation	Vertical
PCB Retention	None
Panel Mount	No
Pitch - Mating Interface	5.08mm (.200")
Pitch - Termination Interface	5.08mm (.200")
Polarized to Mating Part	Yes
Shrouded	Fully
Stackable	No
Surface Mount Compatible (SMC)	No
Temperature Range - Operating	110°C
Wire Size AWG	12, 14, 16, 18, 20, 22, 24, 26


**Electrical**

Current - Maximum per Contact	15A
Voltage - Maximum	300V

**Material Info**

**Reference - Drawing Numbers**

Sales Drawing	SD-39170-003
---------------	--------------

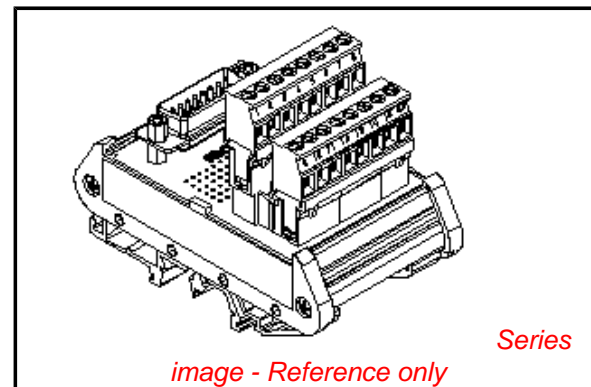

**EU RoHS**

**RoHS Compliance**

**Not Required**

**REACH SVHC**

Not Reviewed

**Low-Halogen Status**

**Not Reviewed**

**China RoHS**

**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

**Search Parts in this Series**

[39170Series](#)