

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0398501610](#)
Status: **Obsolete**
Description: 5.00mm (.197") Pitch Beau™ Eurostyle™ Vertical Fixed Terminal Block, 10 Circuits
Replacement Part Number: [39543-0010](#)

Documents:
[Drawing \(PDF\)](#)

Agency Certification

CSA LR25562
 UL E48521

General

Product Family Terminal Blocks
 Series [39850](#)
 Application Wire-to-Board
 Component Type One Piece
 Product Name Eurostyle™ Fixed Mount
 Replacement Part Number [39543-0010](#)
 Type Euro Block

Physical

Circuits (Loaded) 10
 Circuits (maximum) 10
 Color - Resin Black
 Entry Angle Horizontal
 Flammability 94V-0
 Lock to Mating Part None
 Material - Metal Phosphor Bronze
 Material - Resin Polysulfone
 Number of Rows 1
 Orientation Vertical
 PC Tail Length 3.30mm (.130"), 4.00mm (.157")
 PCB Retention N/A
 PCB Thickness - Recommended 1.60mm (.063")
 Panel Mount No
 Pitch - Mating Interface 5.00mm (.197")
 Pitch - Termination Interface 5.00mm (.197")
 Polarized to Mating Part No
 Shrouded Fully
 Stackable No
 Surface Mount Compatible (SMC) No
 Temperature Range - Operating 110°C
 Wire Size AWG 12, 14, 16, 18, 20, 22

Electrical


Current - Maximum per Contact 20A
 Voltage - Maximum 250V

Material Info

Old Part Number 85510

Reference - Drawing Numbers

Sales Drawing SD-39850-001

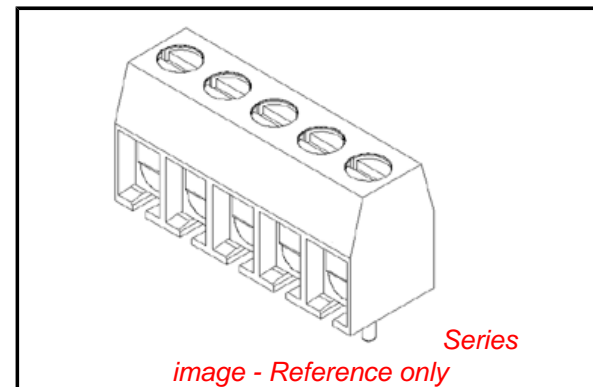

EU RoHS

Not RoHS Compliant
REACH SVHC
 Not Reviewed
Low-Halogen Status
 Not Reviewed

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

[39850Series](#)

This document was generated on 05/09/2011

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION