

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0451320601**
Status: **Active**
Overview: Micro-Fit Connector System
Description: Micro-Fit TPA-to-Micro-Fit TPA Off-the-Shelf (OTS) Cable Assembly, Dual Row, 150.00mm Length, 6 Circuits, Black

Documents:

[Drawing \(PDF\)](#) [Product Literature \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Cable Assemblies
Series	45132
Application	Power, Wire-to-Board, Wire-to-Wire
Assembly Configuration	Dual Ended Connectors
Connector to Connector	Micro-Fit TPA Both Ends
Overmolded	No
Overview	<u>Micro-Fit Connector System</u>
Product Literature Order No	987651-6143
Product Name	Micro-Fit TPA
Type	Discrete Wire Assembly
UPC	889056745246

Physical

Cable Length	150.00mm
Circuits (Loaded)	6
Color - Resin	Black
Gender	Female-Female
Lock to Mating Part	Yes
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Nylon
Net Weight	9.846/g
Number of Rows	2
Packaging Type	Bag
Pitch - Mating Interface	3.00mm
Plating min - Mating	1.016µm
Plating min - Termination	1.016µm
Single Ended	No
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.76mm
Wire Size AWG	20
Wire/Cable Type	UL 1007


Electrical

Current - Maximum per Contact	5.0A
Voltage - Maximum	300V

Material Info

Reference - Drawing Numbers

Sales Drawing	2012341032-000
---------------	----------------

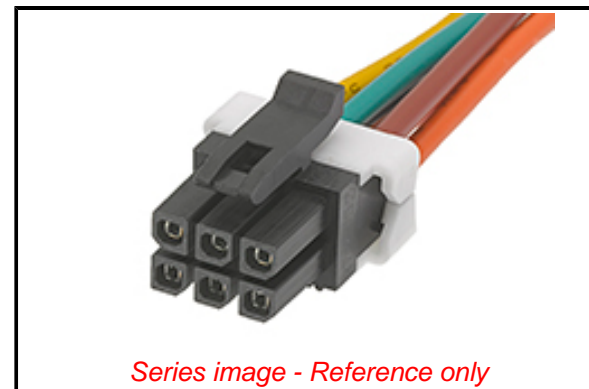

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per
-ED/88/2018 (15
January 2019)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[45132](#) Series

Mates With

Micro-Fit 3.0 Headers [43045](#)
Micro-Fit
3.0 Plug Housings [43020](#)