

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0467090004](#)
Status: **Active**
Overview: [EXTreme Ten60Power High-Current Connector](#)
Description: [EXTreme Ten60Power Signal Housing, 4 Circuits](#)

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Packaging Specification PK-46709-0001 \(PDF\)](#) [Product Literature \(PDF\)](#)

General

Product Family	Crimp Housings
Series	46709
Application	Signal, Wire-to-Board
Comments	Panel Mount when used with Panel-to-Board receptacle housing 172512
Comments	Panel Mount when used with Panel-to-Board receptacle housing 172512
Overview	EXTreme Ten60Power High-Current Connector
Product Literature Order No	987650-1981
Product Name	EXTreme Ten60Power
UPC	889056027908


Physical

Circuits (maximum)	4
Color - Resin	Black
Gender	Female
Glow-Wire Capable	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	0.360/g
Number of Rows	3
Packaging Type	Bag
Panel Mount	Yes
Pitch - Mating Interface	2.54mm
Polarized to Mating Part	Yes
Temperature Range - Operating	-40° to +105°C

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-46709-0001
Sales Drawing	SD-172510-001-001

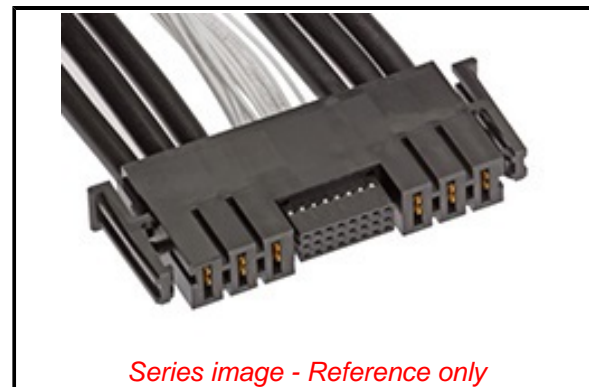

Series image - Reference only

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per
-ED/88/2018 (15
January 2019)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Compliant

Not Contained

Search Parts in this Series

[46709](#) Series

Mates With

EXTreme Ten60Power Plug Assembly
[172453](#) , [172458](#)

Use With

EXTreme Ten60Power Receptacle
Housings [172510](#) , [172512](#) , EXTreme
Ten60Power Signal Terminal [70058](#)