

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0511440900](#)
Status: **Contact Molex**
Description: 3.96mm (.156") Pitch Wire-to-Board Housing, Positive Lock, 9 Circuits

Documents:

3D Model	Product Specification PS-51144-003 (PDF)
Drawing (PDF)	Product Specification PS-87585-031 (PDF)
Product Specification PS-51144-002 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification

CSA	LR19980
TUV	R72090224
UL	E29179

General

Product Family	Crimp Housings
Series	51144
Application	Power, Wire-to-Board
Product Name	N/A


Physical

Circuits (maximum)	9
Color - Resin	Natural
Flammability	94V-0
Gender	Female
Glow-Wire Compliant	No
Material - Resin	Polyester
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	3.96mm (.156")
Stackable	No
Temperature Range - Operating	-40°C to +105°C

Material Info

Reference - Drawing Numbers

Product Specification	PS-51144-002, PS-51144-003, PS-87585-031, RPS-51144-001, RPS-51144-003, RPS-51144-004, RPS-51144-005, RPS-51144-006, RPS-51144-007, RPS-51144-008, RPS-51144-009, RPS-51144-011
Sales Drawing	SD-51144-001

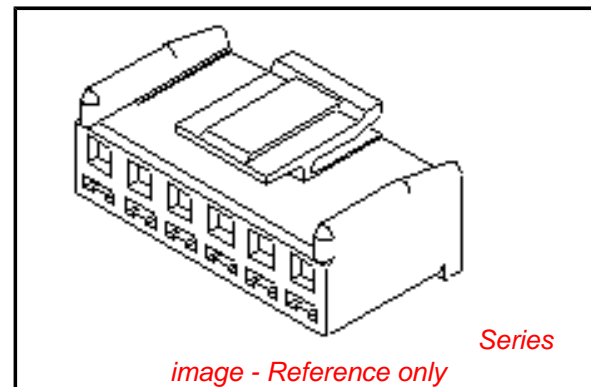

EU RoHS

ELV and RoHS Compliant
REACH SVHC
Contains SVHC: No
Low-Halogen Status
Not Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

[51144Series](#)

Mates With

[53520](#) , [53521](#)

Use With

[50539](#)