

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0730990002](#)
Status: **Active - Custom**
Overview: [cgrid_sl_products](#)
Description: 2.54mm (.100") SL™ Drawer Crimp Housing, Blind Mating, Hermaphroditic, 10 Circuits

Documents:

[3D Model](#) [Test Summary TS-73099-9999 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-73099-9999 \(PDF\)](#)

Agency Certification

CSA LR19980
 UL E29179

General

Product Family Crimp Housings
 Series [73099](#)
 Application Signal
 Comments Custom Configuration Option B
 Overview [cgrid_sl_products](#)
 Product Name SL™


Physical

Circuits (maximum) 10
 Color - Resin Black
 Flammability 94V-0
 Gender Dual
 Glow-Wire Compliant No
 Material - Resin Polyester
 Number of Rows 1
 Packaging Type Bag
 Panel Mount Yes
 Pitch - Mating Interface 2.54mm (.100")
 Stackable No
 Temperature Range - Operating -40°C to +105°C

Material Info

Reference - Drawing Numbers

Product Specification PS-73099-9999
 Sales Drawing SDA-73099-0***
 Test Summary TS-73099-9999

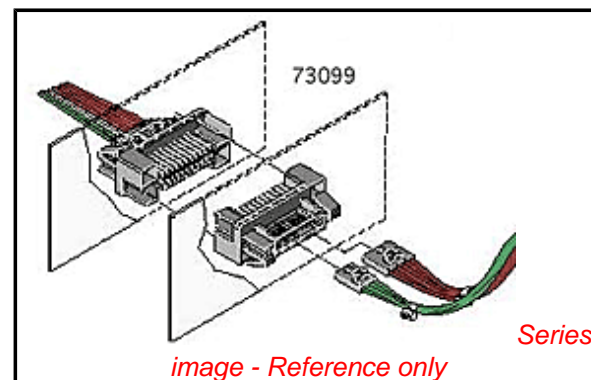

EU RoHS

**ELV and RoHS
 Compliant**

REACH SVHC

Not Reviewed

Low-Halogen Status

Not Low-Halogen

China RoHS



**Need more information on product
 environmental compliance?**

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of
 Compliance, [click here](#)

Please visit the [Contact Us](#) section for any
 non-product compliance questions.

Search Parts in this Series

[73099Series](#)

Mates With

[70400G](#) , [73099](#) , [70066g Housing](#) , [70430g
 Receptacle](#)