

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** **0734035112**  
**Status:** **Active**  
**Overview:** FAKRA PCB, Cable and Sealed Connection Systems  
**Description:** 50 Ohms, FAKRA SMB Jack, Right-Angle, Through Hole, Brass Body, Keying Option C, Blue

**Documents:**

[3D Model](#) [Product Specification PS-89675-331-001 \(PDF\)](#)  
[3D Model \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Drawing \(PDF\)](#)

**General**

Product Family	RF/Coax Connectors
Series	73403
Application	Automotive
Overview	FAKRA PCB, Cable and Sealed Connection Systems
Product Name	FAKRA, SMB
Style	PCB
Type	Subminiature
UPC	883906687632
Wire/Cable Type	N/A

**Physical**

Gender	Jack
Keying to Mating Part	Yes
Net Weight	4.452/g
Orientation	Right Angle
PCB Mounting	Through Hole
Packaging Type	Tray
Panel Mount	No
Panel Mount Method	N/A
Reverse Polar	No

**Electrical**

Frequency	6 GHz
Impedance	50Ω
Power / Voltage	VOLTAGE: 335 Vrms@Sea Level


**Solder Process Data**

Duration at Max. Process Temperature (seconds)	010
Lead-freeProcess Capability	SMC&WAVE
Max. Cycles at Max. Process Temperature	002
Process Temperature max. C	260

**Material Info**

**Reference - Drawing Numbers**

Product Specification	PS-89675-331-001
Sales Drawing	SD-73403-511-001, SD-73403-511-PKG-001, SD-73403-650-001

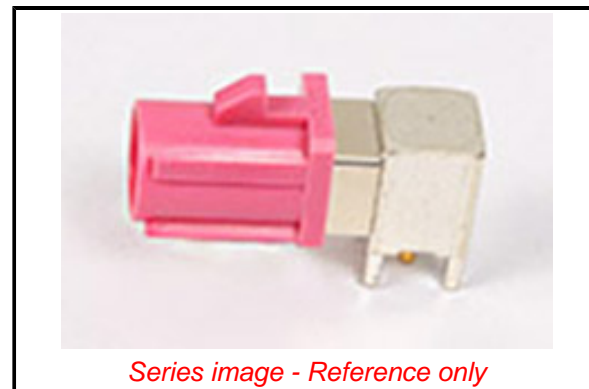

Series image - Reference only

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant with Exemption 6(c)**

**REACH SVHC**

Contained Per - ED/71/2019 (16 July 2019)

Lead

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

50 Image

Not Relevant

Not Contained

**Search Parts in this Series**

73403 Series