

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0901512306](#)  
**Status:** **Active**  
**Overview:** [C-Grid Connector Products](#)  
**Description:** C-Grid III PC Board Connector, Dual Row, Vertical, 6 Circuits, Gold (Au) Plating

**Documents:**

<a href="#">3D Model</a>	<a href="#">Application Specification 713080001-AS-000 (PDF)</a>
<a href="#">Drawing (PDF)</a>	<a href="#">Application Specification 901190001-AS-000 (PDF)</a>
<a href="#">3D Model (PDF)</a>	<a href="#">Packaging Specification PK-90151-001-001 (PDF)</a>
<a href="#">Product Specification PS-99020-0001-001 (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>

**Agency Certification**

UL E29179

**General**


Product Family	PCB Receptacles
Series	<a href="#">90151</a>
Application	Board-to-Board, Signal
Overview	<a href="#">C-Grid Connector Products</a>
Product Name	C-Grid
UPC	800753668393

**Physical**

Circuits (Loaded)	6
Circuits (maximum)	6
Color - Resin	Black
Durability (mating cycles max)	500
Flammability	94HB
Glow-Wire Capable	No
Guide to Mating Part	No
Keying to Mating Part	None
Lock to Mating Part	No
Material - Metal	Phosphor Bronze
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Material - Resin	Polyester
Net Weight	0.507/g
Number of Rows	2
Orientation	Vertical
PC Tail Length	2.60mm
PCB Locator	No
PCB Retention	None
PCB Thickness - Recommended	0.80mm, 1.70mm
Packaging Type	Tube
Pitch - Mating Interface	2.54mm
Pitch - Termination Interface	2.54mm
Plating min - Mating	0.762µm
Plating min - Termination	3.048µm
Polarized to PCB	No
Stackable	Yes
Surface Mount Compatible (SMC)	No
Temperature Range - Operating	-55° to +125°C
Termination Interface: Style	Through Hole

**Electrical**

Current - Maximum per Contact	3.0A
Grounding to PCB	No

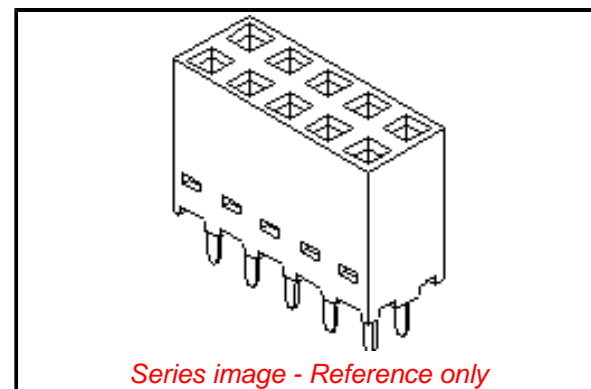

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
D(2020)9139-DC (19  
Jan 2021)

**Halogen-Free**

**Status**

**Not Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[90151 Series](#)

**Mates With**

0.64mm square pins

Voltage - Maximum

350V

**Material Info**

**Reference - Drawing Numbers**

Application Specification

713080001-AS-000, 901190001-AS-000

Packaging Specification

PK-90151-001-001

Product Specification

PS-99020-0001-001

Sales Drawing

SDA-90151-001

This document was generated on 05/31/2021

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**