

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0984381003](#)
Status: **Active**
Description: 5.00mm Pitch NSCC/SICMA Female Wire-to-Board Housing, for 2.80mm Tab, with Bridges, Dual Row, 6 Circuits, Gray

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Application Specification AS-98438-001-001 \(PDF\)](#)

General

Product Family	Crimp Housings
Series	98438
Application	Power, Wire-to-Board
Comments	For current designation please refer to FCI Sicma terminal specification for 2.80mm terminals., For current designation please refer to FCI Sicma terminal specification for 2.80mm terminals.
Product Name	NSCC
UPC	822350104319

Physical

Circuits (maximum)	6
Color - Resin	Black, Natural
Gender	Receptacle
Glow-Wire Capable	No
Lock to Mating Part	Yes
Material - Resin	Polyester
Net Weight	5.162/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	5.00mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C

Solder Process Data


Lead-freeProcess Capability	N/A
-----------------------------	-----

Material Info

Engineering Number	98438-1001
--------------------	------------

Reference - Drawing Numbers

Application Specification	AS-98438-001-001
Sales Drawing	SD-98438-001

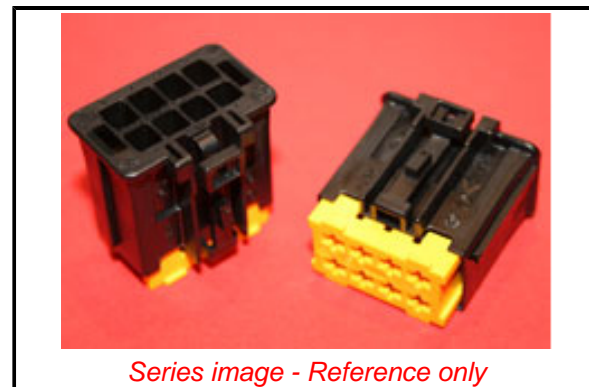

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - ED/61/2018 (27 June 2018)

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Not Relevant

Compliant

Not Contained

Search Parts in this Series

[98438](#) Series

Mates With

[98898](#) UCC2 Terminals

Use With

[98898](#)