

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0423752487](#)
Status: **Active**
Description: KK 100 Hdr Assy Bkwy 03 Ckt 15 SGold

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-10-07-001 \(PDF\)](#)

Agency Certification

CSA LR19980
 UL E29179

General

Product Family PCB Headers
 Series [42375](#)
 Application Tooling Part Link 11-20-1230
 Product Name KK@ 254
 UPC 756054591451

Physical

Flammability 94V-0
 Net Weight 0.360/g

Electrical

Voltage - Maximum 500V


Solder Process Data

Duration at Max. Process Temperature (seconds) 005
 Lead-freeProcess Capability WAVE
 Max. Cycles at Max. Process Temperature 001
 Process Temperature max. C 235

Material Info

Reference - Drawing Numbers

Product Specification PS-10-07-001
 Sales Drawing SD-42375-001

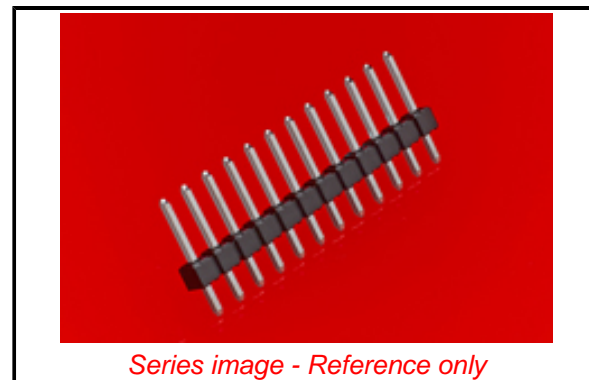

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
 ED/30/2017 (7 July
 2017)

Halogen-Free

Status

Not Low-Halogen

**Need more information on product
 environmental compliance?**

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any
 non-product compliance questions.

China ROHS Green Image
 ELV Not Relevant
 RoHS Phthalates Not Contained

Search Parts in this Series
[42375 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION