

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1501772040](#)
Status: **Active**
Overview: [EconoLatch Wire-to-Wire Interconnects](#)
Description: EconoLatch Plug Housing, Dual Row, with Panel Mount Latch, 4 Circuits

Documents:

3D Model	RoHS Certificate of Compliance (PDF)
Drawing (PDF)	Product Literature (PDF)
3D Model (PDF)	

Agency Certification

UL E29179


General

Product Family	Crimp Housings
Series	150177
Application	Power, Wire-to-Wire
Overview	EconoLatch Wire-to-Wire Interconnects
Product Literature Order No	987651-5541
Product Name	EconoLatch
UPC	889056483254

Physical

Circuits (maximum)	4
Color - Resin	Natural
Flammability	94V-2
Gender	Plug
Glow-Wire Capable	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	1.290/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	Yes
Pitch - Mating Interface	3.68mm
Pitch - Termination Interface	3.68mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C

Material Info

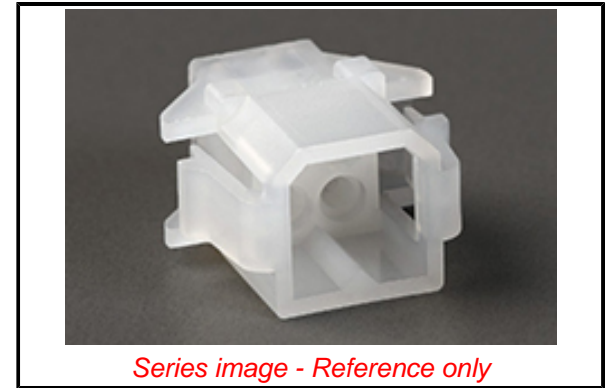

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/71/2019 (16 July
2019)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[150177 Series](#)

Mates With

EconoLatch Receptacle Housing [150179](#)

Use With

EconoLatch Male Terminal [150180](#)