


**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1511920004](#)  
**Status:** **Active**  
**Overview:** Milli-Grid Connector System  
**Description:** 2.00mm Pitch Milli-Grid Receptacle Housing, Dual Row, 4 Circuits, Black, Glow-Wire Capable

**Documents:**

<a href="#">3D Model</a>	<a href="#">Packaging Specification PK-151192-0001 (PDF)</a>
<a href="#">3D Model (PDF)</a>	<a href="#">Datasheet (PDF)</a>
<a href="#">Drawing (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>
<a href="#">Product Specification PS-151192-0001-001 (PDF)</a>	

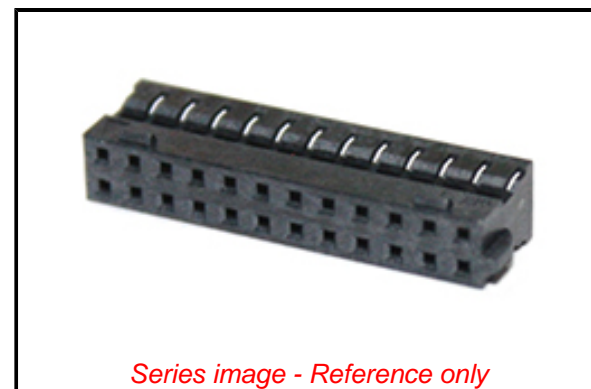

**Agency Certification**

CSA	LR19980
UL	E29179

**General**

Product Family	Crimp Housings
Series	<a href="#">151192</a>
Application	Signal, Wire-to-Board
Datasheet Order No	987651-5501
Overview	<a href="#">Milli-Grid Connector System</a>
Product Name	Milli-Grid
UPC	889056795005

**Physical**

Circuits (maximum)	4
Color - Resin	Black
Flammability	94V-0
Gender	Receptacle
Glow-Wire Capable	Yes
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	Polyester
Net Weight	0.113/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.00mm
Pitch - Termination Interface	2.00mm
Polarized to Mating Part	Yes
Temperature Range - Operating	-55° to +105°C

**Solder Process Data**

Lead-freeProcess Capability	N/A
-----------------------------	-----

**Material Info**

**Reference - Drawing Numbers**

Packaging Specification	PK-151192-0001
Product Specification	PS-151192-0001-001
Sales Drawing	1511921001-000

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per - ED/71/2019 (16 July 2019)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[151192](#) Series

**Mates With**

Milli-Grid Header [151117](#) , [151118](#) , [151119](#) , [151120](#)

**Use With**

Milli-Grid Female Terminal [50394](#)