

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0190670110**
Status: **Active**
Overview: Solderless Terminals
Description: NylaKrimp™ Funnel Entry Ring Tongue Terminal for 2/0 AWG Wire, Stud Size 1/4" (M6)

Documents:

Drawing (PDF) Product Specification PS-19902-016-001 (PDF)
Product Specification PS-19902-011-001 (PDF) RoHS Certificate of Compliance (PDF)
Product Specification PS-19902-013-001 (PDF)

Agency Certification

UL E32244

General

Product Family Ring and Spade Terminals
Series 19067
Crimp Quality Equipment Yes
Mil-Spec N/A
Overview Solderless Terminals
Product Name NylaKrimp™
Type Ring
UPC 800753067011

Physical


Barrel Type Closed - Brazed
Flammability 94V-2
Insulation Nylon (PA)
Material - Plating Mating Tin
Net Weight 50.667/g
Packaging Type Bag
Plating min - Mating 2.540µm
Plating min - Termination 2.540µm
Stud Size 1/4" (M6)
Termination Interface: Style Crimp or Compression
Wire Insulation Diameter 19.43mm max.
Wire Size AWG 2/0

Material Info

Engineering Number J-985-14

Reference - Drawing Numbers

Product Specification PS-19902-011-001, PS-19902-013-001, PS-19902-016-001
Sales Drawing SD-19067-001

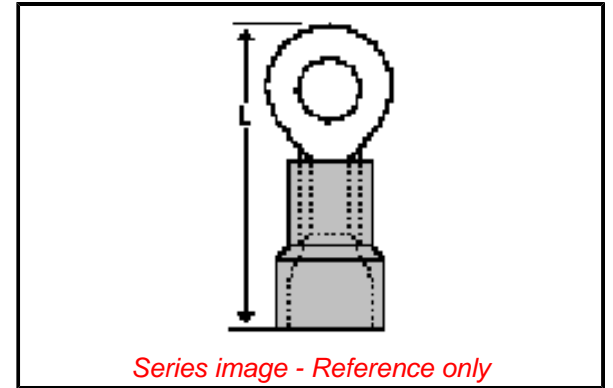

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - ED/108/2014 (17 Dec 2014)

Halogen-Free

Status

Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Reviewed

Search Parts in this Series

19067 Series