

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1731120154](#)  
**Status:** **Active**  
**Overview:** [D-Sub Products](#)  
**Description:** FCT High Power Contact, Male, Straight, PCB Through Hole, 0.10µm Gold over Nickel Phosphorus Plating, 20.0A, 3.15mm PCB Drilling Diameter

**Documents:**

[RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	D-Sub Products
Series	<a href="#">173112</a>
Brochure Order No	987651-9941
Contact Type	High Power
Exclude SD Check	Yes
Overview	<a href="#">D-Sub Products</a>
Product Category	Contacts
Product Name	FCT Products
UPC	889056489096

**Physical**


Durability (mating cycles max)	500
Gender	Male
Material - Contact	Copper Alloy
Material - Plating Mating	Gold over Nickel Phosphorus
Material - Plating Termination	Tin over Nickel
Material - Retaining Clip	Copper Alloy
Net Weight	1.600/g
Orientation	Straight
Packaging Type	Bag
Plating min - Mating	0.100µm
Plating min - Termination	5.000µm
Temperature Range - Operating	-55° to +155°C
Termination Interface: Style	Through Hole

**Electrical**

Current - Maximum per Contact	20.0A
-------------------------------	-------

**Material Info**

Engineering Number	FMP010P203
--------------------	------------

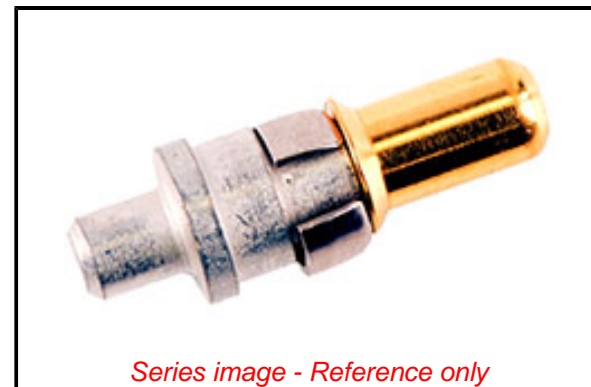

*Series image - Reference only*

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[173112 Series](#)

**Use With**

FCT Mixed Layout Connectors