

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0399400208**
Status: **Active**
Overview: Eurostyle™ Terminal Blocks
Description: 5.08mm Pitch Beau EuroMate Pluggable PCB Terminal Block, Dual Level, 90° Wire Entry, 8 Circuits

Documents:

[3D Model](#) [Product Specification PS-39940-001-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E48521

General

Product Family Terminal Blocks
Series [39940](#)
Application N/A
Comments Gold plating available
Component Type Plug
Overview [Eurostyle™ Terminal Blocks](#)
Product Name EuroMate™ Pluggable
Type Euro Block
UPC 800756371986

Physical

Circuits (Loaded) 8
Color - Resin Black
Entry Angle Horizontal
Flammability 94V-0
Lock to Mating Part None
Material - Resin Nylon
Number of Rows 2
Orientation Vertical
Panel Mount No
Pitch - Mating Interface 5.08mm
Pitch - Termination Interface 5.08mm
Polarized to Mating Part Yes
Stackable No
Temperature Range - Operating 130°C
Termination Interface: Style Screw or Lug
Wire Size AWG 12, 14, 16, 18, 20, 22
Wire Size mm² 0.50-2.50

Electrical


Current - Maximum per Contact 15.0A
Voltage - Maximum 300V

Material Info

Engineering Number 940808

Reference - Drawing Numbers

Product Specification PS-39940-001-001
Sales Drawing SD-39940-004

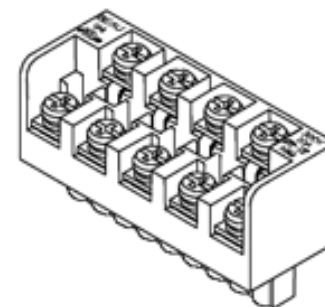

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series

[39940 Series](#)

Mates With

[39531-0008](#) , [39531-1008](#) , [39532-0008](#) , [39532-1008](#)