

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [2138150106](#)
Status: **Active**
Overview: [Mega-Fit Power Connectors](#)
Description: Mega-Fit Plug Housing, Single Row, 6 Circuit, UL 94V-0, Glow-Wire Capable, Free Hanging

Documents:

3D Model	Product Specification 1054171000-PS-SPA-00 (PDF)
Drawing (PDF)	Application Specification 768232000-AS-000 (PDF)
3D Model (PDF)	Packaging Specification 2138150001-PK-000 (PDF)
Product Specification 1054171000-PS-000 (PDF)	Datasheet (PDF)
Product Specification 1054171000-PS-CH-000 (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification 1054171000-PS-KO-000 (PDF)	

General

Product Family	Crimp Housings
Series	213815
Application	Power, Wire-to-Wire
Overview	Mega-Fit Power Connectors
Product Name	Mega-Fit
UPC	193264466290


Physical

Circuits (maximum)	6
Color - Resin	Black
Gender	Plug
Glow-Wire Capable	Yes
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	4.360/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	5.70mm
Pitch - Termination Interface	5.70mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C, -40° to +120°C

Material Info

Reference - Drawing Numbers

Application Specification	768232000-AS-000
Packaging Specification	2138150001-PK-000
Product Specification	1054171000-PS-000, 1054171000-PS-CH-000, 1054171000-PS-KO-000, 1054171000-PS-SPA-00
Sales Drawing	2138150001-SD-000

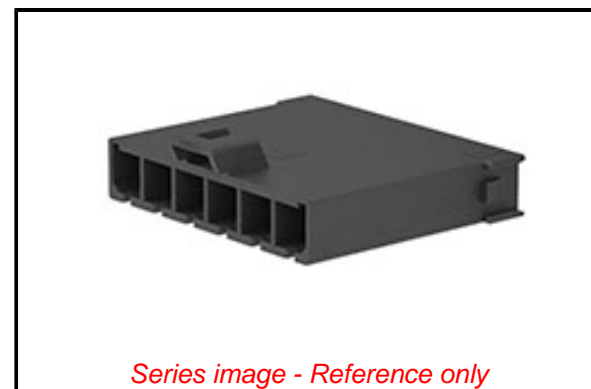

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2020)9139-DC (19
Jan 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[213815 Series](#)

Mates With

Mega-Fit Receptacle Housing [200456](#)

Use With

Mega-Fit TPA [105415](#)
Mega-Fit Crimp
Terminals [105417](#) , [105418](#)