

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** **0436801006**  
**Status:** **Active**  
**Overview:** Sabre™ Power Connector  
**Description:** 7.50mm Pitch Sabre™ Plug Crimp Housing, UL 94V-2, 6 Circuits

**Documents:**

<a href="#">3D Model</a>	<a href="#">Packaging Specification PK-43680-001-001 (PDF)</a>
<a href="#">Drawing (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>
<a href="#">Product Specification PS-44441-9999-001 (PDF)</a>	<a href="#">Product Literature (PDF)</a>

**Agency Certification**

CSA	LR19880
UL	E29179

**General**

Product Family	Crimp Housings
Series	<a href="#">43680</a>
Application	Power, Wire-to-Wire
Application Tooling Part Link	63813-0800
Comments	Positive mating lock and integrated Terminal Position Assurance (TPA) standard.
Overview	<a href="#">Sabre™ Power Connector</a>
Product Literature Order No	987650-5662
Product Name	Sabre™
UPC	822348670567

**Physical**

Circuits (maximum)	6
Color - Resin	Natural
Flammability	94V-2
Gender	Plug
Glow-Wire Compliant	No
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	8.958/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	7.50mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40°C to +75°C

**Electrical**

Current - Maximum per Contact	18.0A
-------------------------------	-------


**Solder Process Data**

Lead-free Process Capability	N/A
------------------------------	-----

**Material Info**

**Reference - Drawing Numbers**

Packaging Specification	PK-43680-001-001
Product Specification	PS-44441-9999-001
Sales Drawing	436800006-000

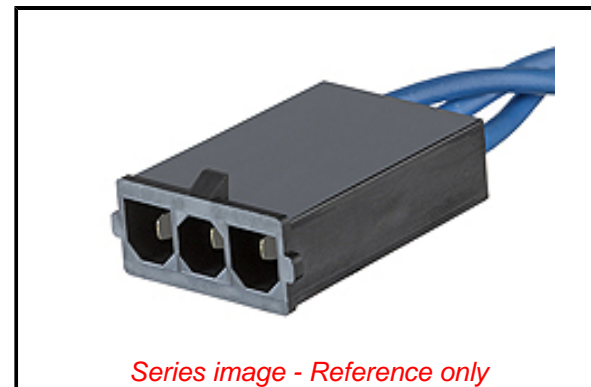

Series image - Reference only

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per - ED/30/2017 (7 July 2017)

**Halogen-Free**

**Status**

**Low-Halogen**

**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

**Search Parts in this Series**

[43680](#) Series

**Mates With**

Receptacle Housing [44441-1006](#)

**Use With**

Male Crimp Terminals [43178](#)

**Application Tooling | FAQ**

*Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.*

**Global**

**Description**

**Product #**

Manual Extraction Tool	<a href="#">0638130800</a>
------------------------	----------------------------

This document was generated on 08/08/2017

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**