

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [5040510401](#)
Status: **Active**
Overview: Pico-Lock™ Connector System
Description: 1.50mm Pitch Pico-Lock™ Crimp Housing, 2.00mm Mated Height, Positive Side Locks, 4 Circuits

Documents:

3D Model	Application Specification AS-504051-001-001 (PDF)
Drawing (PDF)	Application Specification AS-504051-002-001 (PDF)
Product Specification PS-504051-001-001 (PDF)	Packaging Specification SPK-504051-001-001 (PDF)
Product Specification PS-504051-002-001 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification

UL E29179

General

Product Family	Crimp Housings
Series	504051
Application	Wire-to-Board
Overview	Pico-Lock™ Connector System
Product Name	Pico-Lock™
UPC	887191335360

Physical

Circuits (maximum)	4
Color - Resin	Black
Gender	Receptacle
Glow-Wire Compliant	No
Keying to Mating Part	N/A
Lock to Mating Part	Yes
Material - Resin	High Temperature Thermoplastic
Net Weight	55.500/mg
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	1.50mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40°C to +105°C


Electrical

Current - Maximum per Contact 3.0A

Material Info

Reference - Drawing Numbers

Application Specification	AS-504051-001-001, AS-504051-002-001
Packaging Specification	SPK-504051-001-001
Product Specification	PS-504051-001-001, PS-504051-002-001
Sales Drawing	SD-504051-001

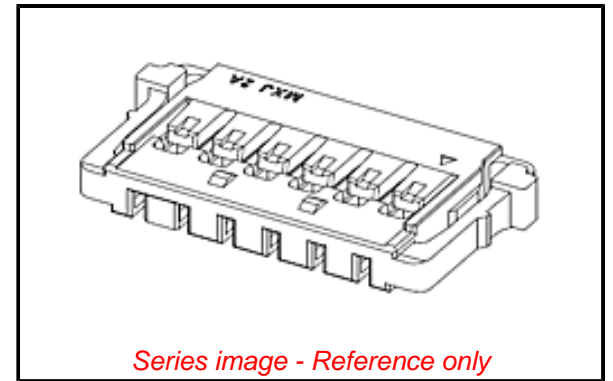

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/30/2017 (7 July 2017)

Halogen-Free Status

Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[504051 Series](#)

Mates With

[504050 Pico-Lock™ SMT Wire-to-Board Header](#)

Use With

[504052 Pico-Lock™ Crimp Terminal](#)