

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0150200429**
Status: **Active**
Overview: Premo-Flex™ Cable Jumpers
Description: 0.50mm Pitch Premo-Flex FFC Jumper, Opposite Side Contacts (Type D), 40 Circuits, 0.076m Cable Length, 0.27mm Cable Thickness, Gold (Au) Plating

Documents:

[Drawing \(PDF\)](#) [Packaging Specification PK-15020-001-001 \(PDF\)](#)
[Product Specification PS-15020-001-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Cable
Series	<u>15020</u>
Comments	Contacts on the same side, Type A
Crimp Quality Equipment	Yes
Overview	<u>Premo-Flex™ Cable Jumpers</u>
Product Name	Premo-Flex™FFC Jumper
UPC	884982178915

Physical

Cable Length	0.076m
Circuits (Loaded)	40
Circuits (maximum)	40
Net Weight	1.018/g
Packaging Type	Bag
Pitch - Termination Interface	0.50mm
Temperature Range - Operating	-40°C to +105°C
Wire Size AWG	N/A
Wire/Cable Type	Flat Flex Cable


Electrical

Current - Maximum per Contact	0.5A
Voltage - Maximum	60V AC

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-15020-001-001
Product Specification	PS-15020-001-001
Sales Drawing	SD-15020-001

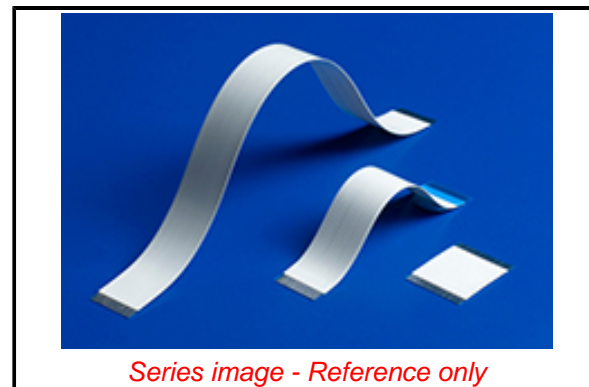

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/108/2014 (17 Dec
2014)

Halogen-Free

Status

Not Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Reviewed

Search Parts in this Series

15020 Series

Use With

Molex FFC – FPC connector. Be sure to match like plating.