

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0394222002](#)
Status: **Active**
Overview: Eurostyle™ Terminal Blocks
Description: 12.00mm Pitch Beau EuroMax Horizontal Plug, with Retention Screws, 2 Circuits, Optional Imprinting

Documents:

[3D Model](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Drawing \(PDF\)](#)

General

Product Family	Terminal Blocks
Series	39422
Application	N/A
Component Type	Plug
Overview	Eurostyle™ Terminal Blocks
Product Name	EuroMax™ Pluggable
Type	Euro Block
UPC	883906833909

Physical

Circuits (Loaded)	2
Color - Resin	Black
Entry Angle	180° Angle
Lock to Mating Part	Yes
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Polyester
Number of Rows	1
Orientation	Horizontal
PCB Retention	N/A
Panel Mount	No
Pitch - Mating Interface	12.00mm
Pitch - Termination Interface	12.00mm
Plating min - Mating	3.810µm
Plating min - Termination	3.810µm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	130°C
Wire Size AWG	10, 12, 14, 3, 4, 6, 8

Electrical


Current - Maximum per Contact	85.0A
Voltage - Maximum	600V

Material Info

Engineering Number	424502-10A
--------------------	------------

Reference - Drawing Numbers

Sales Drawing	SD-39422-001
---------------	--------------

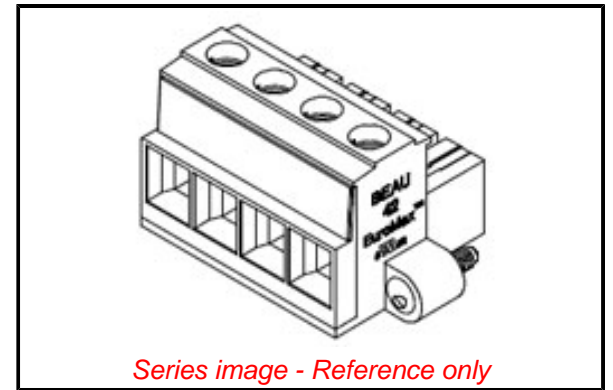

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

[39422](#) Series

Mates With

[39426-0002](#) Horizontal PCB Header, with Threaded Retention Inserts