

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0190090003**
Status: **Active**
Overview: Standard Quick-Disconnect Terminals
Description: VibraKrimp™ Quick Disconnect Flag, Female, for 18-22 AWG Wire

Documents:

[Drawing \(PDF\)](#) [Product Specification PS-19902-013-001 \(PDF\)](#)
[Product Specification PS-19902-005-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#)

Agency Certification

CSA LR18689
 UL E79133

General

Product Family Quick Disconnects
 Series 19009
 Comments Wire Grip
 Crimp Quality Equipment Yes
 Insulated No
 Overview Standard Quick-Disconnect Terminals
 Product Name VibraKrimp™
 Type Quick Disconnect
 UPC 800755046830

Physical

Barrel Type Closed
 Gender Female
 Glow-Wire Compliant No
 Insulation None
 Lock to Mating Part None
 Material - Metal Brass
 Material - Plating Mating Tin
 Material - Plating Termination Tin
 Net Weight 0.647/g
 Orientation Flag
 Packaging Type Bag
 Polarized to Mating Part No
 Tab Thickness 0.51mm
 Tab Width 4.75mm
 Temperature Range - Operating Per Wire Specification
 Wire Insulation Diameter 3.43mm
 Wire Size AWG 18, 20, 22

Electrical


Voltage - Maximum Per Wire Specification

Material Info

Engineering Number AA-4170

Reference - Drawing Numbers

Product Specification PS-19902-005-001, PS-19902-011-001,
 PS-19902-013-001
 Sales Drawing CDFGS187

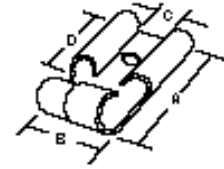

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 ED/30/2017 (7 July
 2017)

Halogen-Free

Status

Low-Halogen

**Need more information on product
 environmental compliance?**

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any
 non-product compliance questions.

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series

19009 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION