

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0192130008](#)
Status: **Active**
Overview: [Wire Pins](#)
Description: Avikrimp™ Wire Pin Terminal for 12-10 AWG Wire, Mylar Tape Carrier

Documents:

[3D Model](#) [Product Specification PS-19902-015-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#)

Agency Certification

CSA LR18689
 UL E32244

General

Product Family Crimp Terminals
 Series [19213](#)
 Application Power
 Comments Pin Length 11.68mm
 Crimp Quality Equipment Yes
 Overview [Wire Pins](#)
 Packaging Alternative [19213-0007](#) (Loose)
 Product Name Wire Pin
 UPC 800753053489

Physical


Flammability 94V-2
 Gender Male
 Material - Metal Copper
 Material - Plating Mating Tin
 Net Weight 2.203/g
 Packaging Type Adhesive Tape on Reel
 Plating min - Mating 1.016µm
 Termination Interface: Style Crimp or Compression
 Wire Insulation Diameter 6.35mm max.
 Wire Size AWG 10, 12
 Wire Size mm² N/A

Material Info

Engineering Number WP-8210T

Reference - Drawing Numbers

Product Specification PS-19902-011-001, PS-19902-015-001
 Sales Drawing SD-19213-002

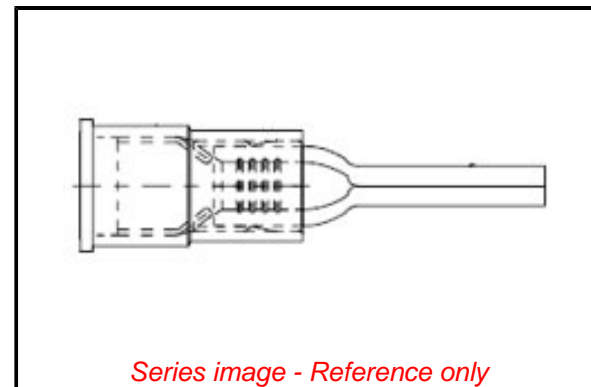

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 ED/30/2017 (7 July
 2017)

Halogen-Free

Status

Low-Halogen

**Need more information on product
 environmental compliance?**

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any
 non-product compliance questions.

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[19213 Series](#)