


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0191600042
Status: Active
Overview: Splices
Description: Twist Lock Splice for 10-22 AWG Wire, Yellow

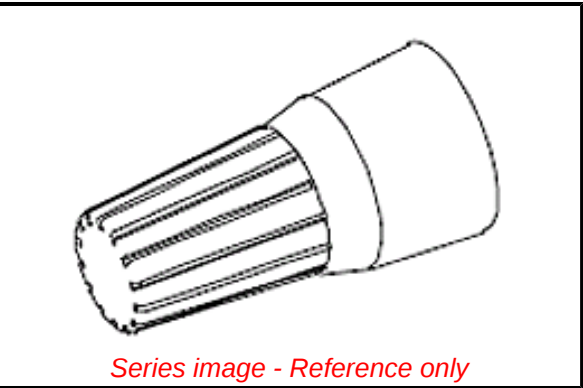

Series image - Reference only

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-19902-013-001 \(PDF\)](#)

Agency Certification	
CSA	LR700095
UL	E32244
General	
Product Family	Splices
Series	19160
Crimp Quality Equipment	Yes
Mil-Spec	N/A
MolexKits	Yes
Overview	Splices
Product Name	Closed-End Twist Lock
UPC	800753110465
Physical	
Barrel Type	Closed
Color - Resin	Yellow
Flammability	94V-2
Insulation	Nylon (PA)
Material - Metal	Copper
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	1.984/g
Packaging Type	Bag
Temperature Range - Operating	105°C
Wire Insulation Diameter	11.18mm max.
Wire Size AWG	10, 12, 14, 16, 18, 20, 22, 24, 26
Electrical	
Voltage - Maximum	600V
Material Info	
Engineering Number	TL-Y
Reference - Drawing Numbers	
Product Specification	PS-19902-013-001
Sales Drawing	SD-19160-005

EU ELV
Not Relevant

EU RoHS **China RoHS**
Compliant
REACH SVHC
Not Contained Per -
ED/30/2017 (7 July
2017)
Halogen-Free
Status
Low-Halogen

**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS Green Image
ELV Not Relevant
RoHS Phthalates Not Contained

Search Parts in this Series
[19160 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION