

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0190340009](#)
Status: **Active**
Overview: [Snap Plugs and Receptacles](#)
Description: InsulKrimp™ Snap Plug, for 14-16 AWG Wire, 22.61mm Length

Documents:
[3D Model](#)
[Drawing \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#)
[Product Specification PS-19902-013-001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR18689
UL E152602

General

Product Family Quick Disconnects
Series [19034](#)
Crimp Quality Equipment Yes
Insulated Partial
MolexKits Yes
Overview [Snap Plugs and Receptacles](#)
Product Name InsulKrimp™
Type Snap Plug
UPC 800753047402

Physical

Barrel Type Closed
Color - Resin Blue
Flammability 94V-0
Gender Male
Glow-Wire Compliant No
Insulation PVC
Lock to Mating Part None
Material - Metal Copper
Material - Plating Mating Tin
Material - Plating Termination Tin
Material - Resin PVC
Net Weight 1.297/g
Orientation Straight
Packaging Type Bag
Tab Thickness N/A
Tab Width N/A
Wire Insulation Diameter 4.40mm max.
Wire Size AWG 14, 16
Wire Size mm² 1.30-2.00

Electrical


Voltage - Maximum 600V

Material Info

Engineering Number B-289X

Reference - Drawing Numbers

Product Specification PS-19902-011-001, PS-19902-013-001
Sales Drawing SD-19034-004

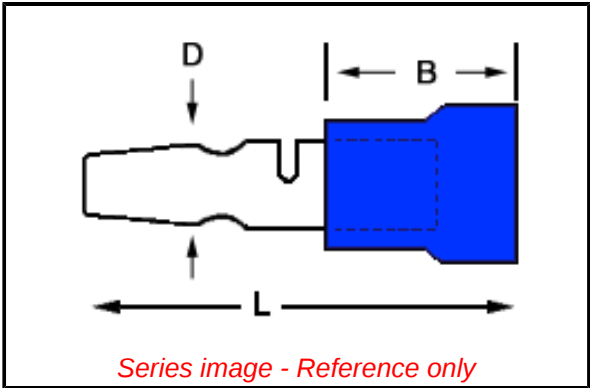

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/30/2017 (7 July
2017)

Halogen-Free

Status

Not Low-Halogen

**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[19034 Series](#)

This document was generated on 08/02/2017

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION