

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0986581211](#)  
**Status:** **Active**  
**Overview:** [MOX Products](#)  
**Description:** MOX Crimp Terminal, Female, 0.635mm, 20-24 AWG (0.22-0.60mm<sup>2</sup>), Reel, Tin (Sn)

**Documents:**

<a href="#">3D Model</a>	<a href="#">Application Specification AS-501352-001 (PDF)</a>
<a href="#">Drawing (PDF)</a>	<a href="#">Application Specification AS-98658-001-001 (PDF)</a>
<a href="#">Product Specification PS-500993-002-001 (PDF)</a>	<a href="#">Application Specification AS-98658-001-CH-001 (PDF)</a>
<a href="#">Product Specification PS-98658-005-001 (PDF)</a>	<a href="#">Application Specification AS-98944-005-001 (PDF)</a>
<a href="#">Application Specification AS-500993-001-001 (PDF)</a>	<a href="#">Packaging Specification 313025040-000 (PDF)</a>
<a href="#">Application Specification AS-500993-002-001 (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>

**General**

Product Family	Crimp Terminals
Series	<a href="#">98658</a>
Application	Power
Comments	Terminal has Stainless Steel Sleeve
Crimp Quality Equipment	Yes
Overview	<a href="#">MOX Products</a>
Product Name	MOX
UPC	800753127418

**Physical**

Durability (mating cycles max)	20
Gender	Female
Material - Metal	High Performance Alloy (HPA), Stainless Steel
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	0.120/g
Packaging Type	Reel
Plating min - Mating	1.016µm
Plating min - Termination	1.016µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.20-1.80mm
Wire Size AWG	20, 22
Wire Size mm <sup>2</sup>	0.22-0.60

**Electrical**

Current - Maximum per Contact	7.5A
-------------------------------	------


**Solder Process Data**

Lead-freeProcess Capability	N/A
-----------------------------	-----

**Material Info**

**Reference - Drawing Numbers**

Application Specification	AS-500993-001-001, AS-500993-002-001, AS-501352-001, AS-98658-001-001, AS-98658-001-CH-001, AS-98944-005-001
Packaging Specification	313025040-000
Product Specification	PS-500993-002-001, PS-98658-005-001
Sales Drawing	SD-98658-004

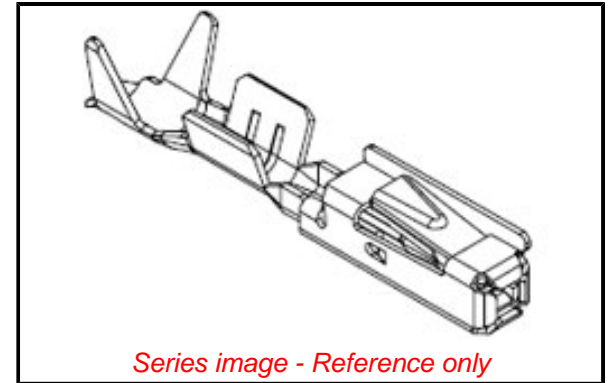

**EU ELV**

**Compliant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per - ED/30/2017 (7 July 2017)

**Halogen-Free**

**Status**

**Low-Halogen**

**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

ELV

RoHS Phthalates

Green Image

Compliant

Not Contained

**Search Parts in this Series**

[98658](#) Series

**Use With**

all 0.635mm MOX Housings

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**