

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0358250211](#)  
**Status:** **Active**  
**Description:** 5.00mm Pitch Automotive Horn Female Housing, Vertical, 2 Circuits for 2.28mm Tab

**Documents:**

[Drawing \(PDF\)](#)      [Packaging Specification PK-35825-002-002 \(PDF\)](#)  
[Packaging Specification PK-35825-001-001 \(PDF\)](#)      [RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family      Crimp Housings  
Series      [35825](#)  
Application      Power  
Product Name      N/A  
UPC      800755998764

**Physical**

Circuits (maximum)      2  
Color - Resin      Black, Yellow  
Gender      Receptacle  
Glow-Wire Compliant      No  
Keying to Mating Part      None  
Lock to Mating Part      Yes  
Material - Resin      Polyester  
Net Weight      5.240/g  
Number of Rows      1  
Packaging Type      Bag  
Panel Mount      No  
Pitch - Mating Interface      5.00mm  
Stackable      No  
Temperature Range - Operating      -40°C to +120°C


**Solder Process Data**

Lead-free Process Capability      N/A

**Material Info**

**Reference - Drawing Numbers**

Packaging Specification      PK-35825-001-001, PK-35825-002-002  
Sales Drawing      SD-35825-0211

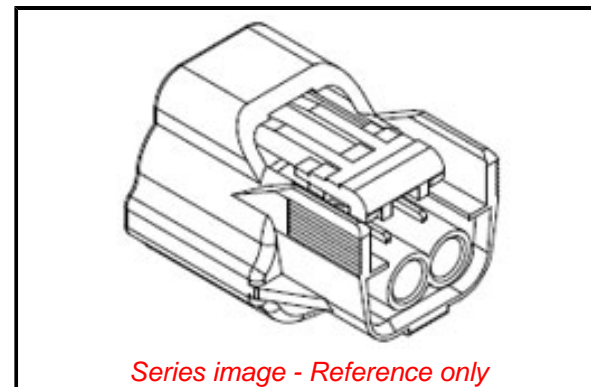

*Series image - Reference only*

**EU ELV**

**Compliant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
ED/30/2017 (7 July  
2017)

**Halogen-Free**

**Status**

**Not Reviewed**

**Need more information on product  
environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
Please visit the [Contact Us](#) section for any  
non-product compliance questions.

China ROHS

Not Relevant

ELV

Compliant

RoHS Phthalates

Not Contained

**Search Parts in this Series**

[35825](#) Series

**Mates With**

Automotive Filtered Horn Header [68131](#)

**Use With**

Terminal [35407](#) , [35903](#)