

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0010013046
Status: Active
Overview: SPOX™ Wire-to-Board Connectors
Description: 5.08mm Pitch SPOX™ Crimp Terminal Housing, 4 Circuits

Documents:
[3D Model](#)
[Drawing \(PDF\)](#)
[Product Specification PS-5197-001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)


Agency Certification
CSA LR19980
UL E29179

General
Product Family Crimp Housings
Series 5197
Application Signal, Wire-to-Board
Overview SPOX™ Wire-to-Board Connectors
Product Name SPOX™
UPC 800754313131

Physical
Circuits (maximum) 4
Color - Resin Natural
Flammability 94V-2
Gender Receptacle
Glow-Wire Compliant No
Material - Resin Nylon
Net Weight 1535.800/mg
Number of Rows 1
Packaging Type Bag
Panel Mount No
Pitch - Mating Interface 5.08mm
Stackable No
Temperature Range - Operating -40°C to +105°C

Material Info
Engineering Number 5197-04

Reference - Drawing Numbers
Product Specification PS-5197-001
Sales Drawing SD-5197-N

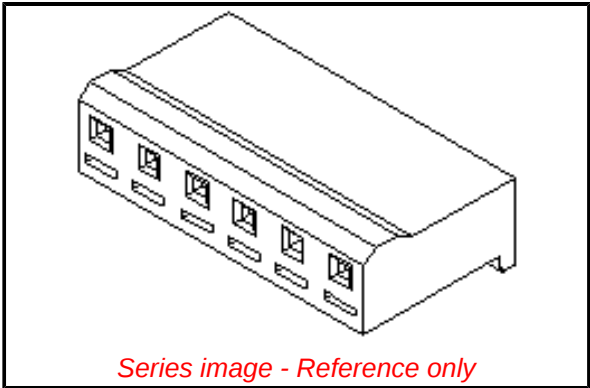

EU ELV
Not Relevant

EU RoHS **China RoHS**
Compliant
REACH SVHC
Not Contained Per -
ED/30/2017 (7 July
2017)
Halogen-Free
Status
Low-Halogen
**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[5197 Series](#)

Mates With
[5281](#) , [5282](#)

Use With
[5194](#) , [5225](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION