

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0190770008**
Status: **Active**
Overview: Solderless Terminals
Description: Avikrimp™ Star Ring Tongue Terminal for 18-22 AWG Wire, Stud Size 10 (M5), Mylar Tape Carrier

Documents:

[3D Model](#) [Product Specification PS-19902-011-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR18689
 UL E32244

General

Product Family Ring and Spade Terminals
 Series 19077
 Crimp Quality Equipment Yes
 Mil-Spec N/A
 Overview Solderless Terminals
 Product Name Avikrimp™
 Type Ring
 UPC 800753080751

Physical


Barrel Type Closed
 Flammability 94V-2
 Insulation Nylon (PA)
 Material - Plating Mating Tin
 Net Weight 0.734/g
 Packaging Type Adhesive Tape on Reel
 Plating min - Mating 2.540µm
 Plating min - Termination 2.540µm
 Stud Size 10 (M5)
 Termination Interface: Style Crimp or Compression
 Wire Insulation Diameter 3.51mm max.
 Wire Size AWG 18, 20, 22

Material Info

Engineering Number SRA-829-10T

Reference - Drawing Numbers

Product Specification PS-19902-011-001
 Sales Drawing SD-19077-001

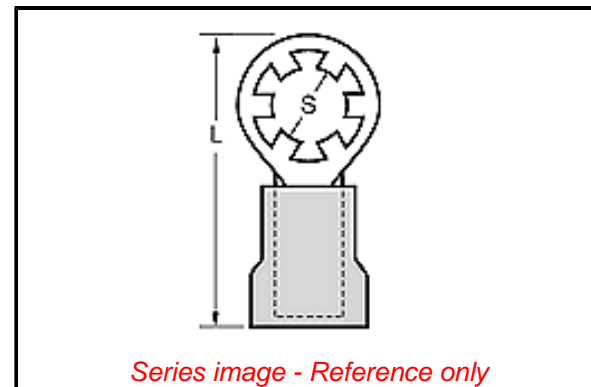

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per
 -ED/01/2017 (12
 January 2017)

Halogen-Free

Status

Not Low-Halogen

**Need more information on product
 environmental compliance?**

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any
 non-product compliance questions.

China ROHS Not Relevant
 ELV Not Relevant
 RoHS Phthalates Not Contained

Search Parts in this Series

[19077 Series](#)