

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0191290047
Status: Active
Overview: Solderless Terminals
Description: Krimptite™ Block Spade Terminal for 18-22 AWG Wire

Documents:
[Drawing \(PDF\)](#) [Product Specification PS-19902-013-001 \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification
CSA LR18689
UL E32244


General
Product Family Ring and Spade Terminals
Series 19129
Crimp Quality Equipment Yes
Mil-Spec N/A
Overview Solderless Terminals
Product Name Krimptite™
Type Spade Block
UPC 800755084009

Physical
Barrel Type Closed
Insulation None
Material - Plating Mating Tin
Net Weight 0.461/g
Packaging Type Bag
Plating min - Mating 2.540µm
Plating min - Termination 2.540µm
Stud Size 5-6 (M3-3.5)
Termination Interface: Style Crimp or Compression
Wire Size AWG 18, 20, 22
Wire Size mm² 0.35-0.80

Solder Process Data
Lead-freeProcess Capability N/A

Material Info
Engineering Number AA-134-06

Reference - Drawing Numbers
Product Specification PS-19902-011-001, PS-19902-013-001
Sales Drawing AACD10301

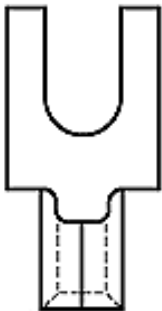

Series image - Reference only

EU ELV
Not Relevant

EU RoHS Compliant REACH SVHC Not Contained Per -ED/01/2017 (12 January 2017) Halogen-Free Status Low-Halogen	China RoHS
--	-------------------

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[19129 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION