

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0877591050**
Status: **Active**
Overview: Milli-Grid™ Connector System
Description: Milli-Grid™ Header, Surface Mount, Vertical, 10 Circuits, 0.38µm Gold (Au) Selective Plating, with Press-fit Plastic Pegs, Lead-Free

Documents:

[3D Model](#) [Packaging Specification PK-89990-475 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-87761-100 \(PDF\)](#)

Agency Certification

UL E29179

General


Product Family PCB Headers
Series 87759
Application Board-to-Board, Signal
Overview Milli-Grid™ Connector System
Product Name Milli-Grid™
UPC 822348283446

Physical

Breakaway Yes
Circuits (Loaded) 10
Circuits (maximum) 10
Color - Resin Black
Durability (mating cycles max) 100
First Mate / Last Break No
Flammability 94V-0
Glow-Wire Compliant No
Guide to Mating Part No
Keying to Mating Part None
Lock to Mating Part None
Mated Height 3.80mm
Material - Metal Phosphor Bronze
Material - Plating Mating Gold
Material - Plating Termination Tin
Material - Resin High Temperature Thermoplastic
Net Weight 0.245/g
Number of Rows 2
Orientation Vertical
PCB Locator Yes
PCB Retention None
Packaging Type Tube
Pitch - Mating Interface 2.00mm
Pitch - Termination Interface 2.00mm
Plating min - Mating 0.381µm
Polarized to Mating Part No
Polarized to PCB No
Shrouded No
Stackable Yes
Temperature Range - Operating -55°C to +125°C
Termination Interface: Style Surface Mount

Electrical

Current - Maximum per Contact 2.0A

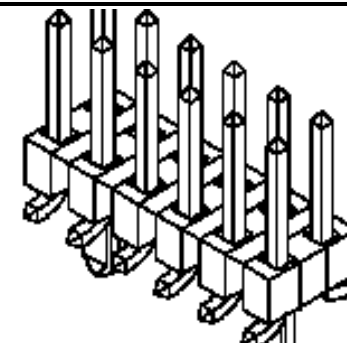

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per
-ED/01/2017 (12
January 2017)

Halogen-Free

Status

Not Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

87759 Series

Mates With

Milli-Grid™ Vertical Through Hole Receptacle [79107](#) , [78787](#) , Milli-Grid™ Flex-to-Board Vertical Receptacle [79108](#) , Milli-Grid™ Vertical Surface Mount Receptacle [79109](#) , [78788](#) , Milli-Grid™ Top Entry Surface Mount Receptacle [87381](#) , Milli-Grid™ Crimp Housing [51110](#)

Voltage - Maximum 125V

Solder Process Data

Duration at Max. Process Temperature (seconds) 010

Lead-free Process Capability REFLOW

Max. Cycles at Max. Process Temperature 003

Process Temperature max. C 260

Material Info

Reference - Drawing Numbers

Packaging Specification PK-89990-475

Product Specification PS-87761-100

Sales Drawing SD-87759-113

This document was generated on 07/24/2017

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION