

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0347960202](#)
Status: **Active**
Overview: [MX150™ Unsealed Connector System](#)
Description: MX150™ Cable Unsealed Female Connector, Single Row, 2 Circuits, Polarization B, Natural

Documents:

[3D Model](#) [Packaging Specification PK-31301-695 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family Crimp Housings
 Series [34796](#)
 Application Power, Wire-to-Wire
 Overview [MX150™ Unsealed Connector System](#)
 Polarization B
 Product Name MX150™ Unsealed
 UPC 884982969469

Physical

Circuits (maximum) 2
 Color - Resin Natural
 Gender Receptacle
 Glow-Wire Compliant No
 Keying to Mating Part Yes
 Lock to Mating Part Yes
 Material - Resin PBT
 Net Weight 2.010/g
 Number of Rows 1
 Packaging Type Bag
 Panel Mount No
 Pitch - Mating Interface 3.50mm
 Pitch - Termination Interface 3.50mm
 Polarized to Mating Part Yes
 Stackable No
 Temperature Range - Operating -40°C to +105°C

Electrical

Current - Maximum per Contact 22.0A


Solder Process Data

Lead-freeProcess Capability N/A

Material Info

Reference - Drawing Numbers

Packaging Specification PK-31301-695
 Sales Drawing SD-34796-001

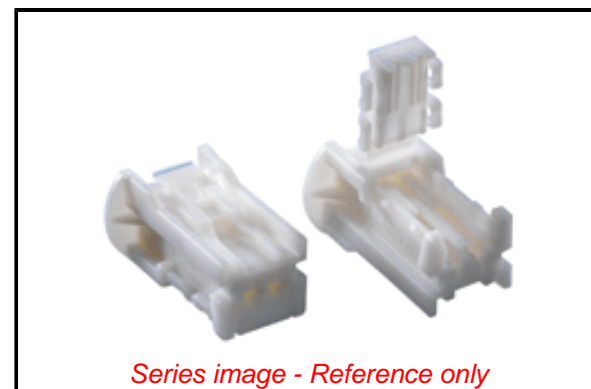

Series image - Reference only

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 ED/30/2017 (7 July
 2017)

Halogen-Free

Status

Not Relevant

Need more information on product environmental compliance?

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Relevant
ELV	Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series

[34796](#) Series

Mates With

[34797](#) 3.50mm Pitch MX150™ Cable Unsealed Male

Use With

MX150™ Female Terminal [33012-2021](#) , [33012-2022](#) , [33012-2023](#) , [33012-3021](#) , [33012-3022](#) , [33012-3023](#)