

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** **0190670096**  
**Status:** **Active**  
**Overview:** Solderless Terminals  
**Description:** NylaKrimp™ Funnel Entry Ring Tongue Terminal for 2 AWG Wire, Stud Size 1/4" (M6)

**Documents:**

[Drawing \(PDF\)](#) [Product Specification PS-19902-016-001 \(PDF\)](#)  
[Product Specification PS-19902-011-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Product Specification PS-19902-013-001 \(PDF\)](#)

**Agency Certification**

CSA LR18689  
 UL E32244

**General**

Product Family Ring and Spade Terminals  
 Series 19067  
 Crimp Quality Equipment Yes  
 Mil-Spec N/A  
 Overview Solderless Terminals  
 Product Name NylaKrimp™  
 Type Ring  
 UPC 800753066762

**Physical**


Barrel Type Closed - Brazed  
 Flammability 94V-2  
 Insulation Nylon (PA)  
 Material - Plating Mating Tin  
 Net Weight 15.704/g  
 Packaging Type Bag  
 Plating min - Mating 2.540µm  
 Plating min - Termination 2.540µm  
 Stud Size 1/4" (M6)  
 Termination Interface: Style Crimp or Compression  
 Wire Insulation Diameter 15.24mm max.  
 Wire Size AWG 2

**Material Info**

Engineering Number G-975-14

**Reference - Drawing Numbers**

Product Specification PS-19902-011-001, PS-19902-013-001,  
 PS-19902-016-001  
 Sales Drawing SD-19067-005

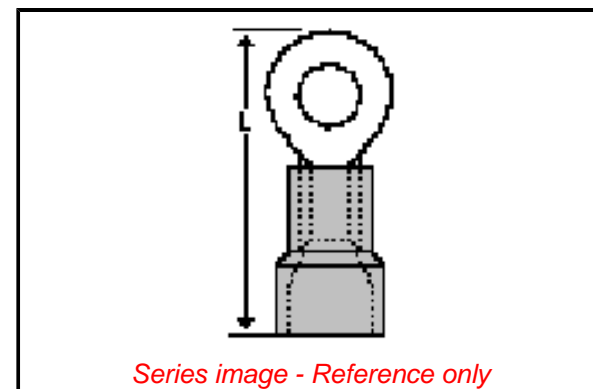

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per  
 -ED/01/2017 (12  
 January 2017)

**Halogen-Free**

**Status**

**Low-Halogen**

**Need more information on product  
 environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
 Please visit the [Contact Us](#) section for any  
 non-product compliance questions.

China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Contained

**Search Parts in this Series**

[19067 Series](#)