

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0192160002](#)
Status: **Active**
Overview: [Splices](#)
Description: Multi-Lock Connector for 10-12 AWG Wire

Documents:

[3D Model](#) [Product Specification PS-19902-013-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#)

Agency Certification

UL E32244

General

Product Family Splices
 Series [19216](#)
 Comments 17.78 x 12.70mm when closed
 Crimp Quality Equipment Yes
 Mil-Spec N/A
 MolexKits Yes
 Overview [Splices](#)
 Product Name Multi-Lock
 UPC 800753056107

Physical

Barrel Type Closed
 Color - Resin Yellow
 Flammability 94V-0
 Insulation Polypropylene
 Material - Metal Copper
 Material - Plating Mating Tin
 Material - Plating Termination Tin
 Net Weight 2.900/g
 Packaging Type Bag
 Temperature Range - Operating 105°C
 Wire Insulation Diameter 4.83mm & 4.32mm
 Wire Size AWG 10, 12
 Wire Size mm² N/A

Electrical

Voltage - Maximum 600V

Solder Process Data


Lead-freeProcess Capability N/A

Material Info

Engineering Number ML-1210

Reference - Drawing Numbers

Product Specification PS-19902-011-001, PS-19902-013-001
 Sales Drawing SD-19216-003

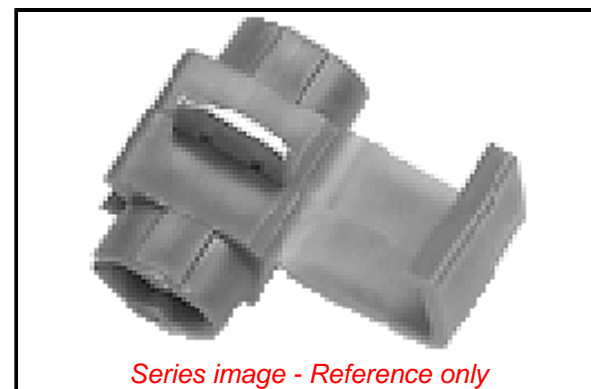

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Contained Per -
 ED/30/2017 (7 July
 2017)
 2,4-Di-tert-butyl-6-(5-
 chlorobenzotriazol-2-
 yl)p

Halogen-Free

Status

Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[19216 Series](#)