

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [019200002](#)
Status: **Active**
Overview: [Splices](#)
Description: Avikrimp™ Seamless Butt Splice for 18-22 AWG Wire, Super Duty

Documents:

Drawing (PDF)	Product Specification PS-19902-013-001 (PDF)
Product Specification PS-19902-011-001 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification

UL E32244

General

Product Family	Splices
Series	19200
Comments	Red
Crimp Quality Equipment	Yes
Mil-Spec	N/A
Overview	Splices
Product Name	Avikrimp™
UPC	756054241226

Physical

Barrel Type	Closed
Color - Resin	Red
Flammability	94V-2
Insulation	Nylon (PA)
Material - Metal	Copper
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	1.593/g
Packaging Type	Bag
Temperature Range - Operating	105°C
Wire Insulation Diameter	3.50mm
Wire Size AWG	18, 20, 22

Electrical


Voltage - Maximum 600V

Material Info

Engineering Number AS-845

Reference - Drawing Numbers

Product Specification	PS-19902-011-001, PS-19902-013-001
Sales Drawing	SD-19200-001

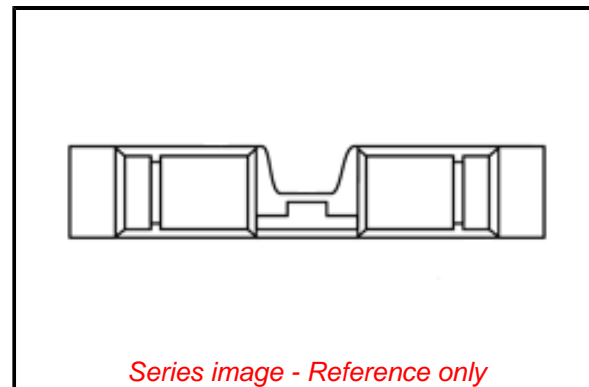

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/30/2017 (7 July
2017)

Halogen-Free

Status

Low-Halogen

**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[19200 Series](#)