

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0351810200](#)  
**Status:** **Active**  
**Description:** 1.78mm Tab Multiple Wire-to-Wire Female Housing, 2 Circuits, Vertical, Type A

**Documents:**

[3D Model](#) [Packaging Specification 351810200-100 \(PDF\)](#)  
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Product Specification PS-35182-003-001 \(PDF\)](#)

**Agency Certification**

CSA LR19980  
 UL E29179

**General**

Product Family Crimp Housings  
 Series [35181](#)  
 Application Power, Wire-to-Wire  
 Product Name N/A  
 UPC 800754376051


**Physical**

Circuits (maximum) 2  
 Color - Resin Natural  
 Flammability 94V-0  
 Gender Receptacle  
 Glow-Wire Compliant No  
 Material - Resin Polyester  
 Net Weight 1.566/g  
 Number of Rows 2  
 Packaging Type Bag  
 Panel Mount No  
 Pitch - Mating Interface 8.00mm  
 Stackable No  
 Temperature Range - Operating -40°C to +120°C

**Material Info**

**Reference - Drawing Numbers**

Packaging Specification 351810200-100  
 Product Specification PS-35182-003-001  
 Sales Drawing SD-35181-020\*

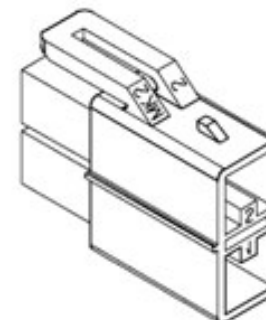

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
 ED/30/2017 (7 July  
 2017)

**Halogen-Free**

**Status**

**Not Low-Halogen**

**Need more information on product  
 environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
 Please visit the [Contact Us](#) section for any  
 non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

**Search Parts in this Series**

[35181](#) Series

**Mates With**

[35180](#) Wire-to-Wire Male Housing

**Use With**

[35746](#) VersaBlade™ Crimp Terminal, [35182](#)  
 VersaBlade™ Wire-to-Wire Male Housing  
 TPA™