

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0191390061](#)  
**Status:** **Active**  
**Overview:** Solderless Terminals  
**Description:** Avikrimp™ Block Spade Terminal for 10-12 AWG Wire

**Documents:**

[Drawing \(PDF\)](#) [Product Specification PS-19902-013-001 \(PDF\)](#)  
[Product Specification PS-19902-011-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

CSA LR18689  
 UL E32244

**General**

Product Family Ring and Spade Terminals  
 Series [19139](#)  
 Crimp Quality Equipment Yes  
 Mil-Spec N/A  
 Overview [Solderless Terminals](#)  
 Product Name Avikrimp™  
 Type Spade Block  
 UPC 800753102927

**Physical**

Barrel Type Closed  
 Flammability 94V-2  
 Insulation Nylon (PA)  
 Material - Plating Mating Tin  
 Net Weight 2.203/g  
 Packaging Type Bag  
 Stud Size 10 (M5)  
 Wire Insulation Diameter 5.70mm max.  
 Wire Size AWG 10, 12  
 Wire Size mm² 3.30-5.00

**Solder Process Data**


Lead-freeProcess Capability N/A

**Material Info**

Engineering Number C-8105-10

**Reference - Drawing Numbers**

Product Specification PS-19902-011-001, PS-19902-013-001  
 Sales Drawing CCD80301

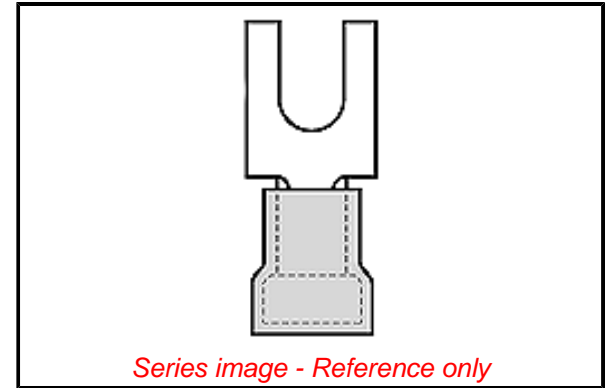

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per  
 -ED/01/2017 (12  
 January 2017)

**Halogen-Free**

**Status**

**Low-Halogen**

**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
 Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[19139 Series](#)

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**