

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0194031010**
Status: **Active**
Overview: Self-Contained Power Connector (SCPC)
Description: Self-Contained Power Connector for Stranded Nonmetallic Sheathed Cable, 12 AWG

Documents:

[3D Model](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Drawing \(PDF\)](#) [Product Literature \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#)

Agency Certification

CSA LR18689
 UL E182087

General


Product Family I/O Connectors
 Series 19403
 Application Wire-to-Wire
 Comments Used-wire boats and many other applications using 110 and 220 AC circuits
 Component Type Plug, Receptacle
 Overview Self-Contained Power Connector (SCPC)
 Product Literature Order No 987650-0531
 Product Name SCPC
 Type N/A
 UPC 800753112681

Physical

Circuits (Loaded) 2
 Circuits (maximum) 2
 Circuits Detail 2 Circuits with Ground
 Color - Resin Clear, Natural
 Durability (mating cycles max) 250
 Flammability 94-5VA
 Lock to Mating Part Yes
 Material - Metal High Copper
 Material - Plating Mating Tin
 Material - Plating Termination Tin
 Material - Resin Polycarbonate, Polyester
 Net Weight 27.307/g
 Number of Rows 1
 Orientation Vertical
 PCB Retention N/A
 Packaging Type Bag
 Panel Mount No
 Pitch - Mating Interface 10.10mm
 Plating min - Mating 2.540µm
 Plating min - Termination 2.540µm
 Polarized to Mating Part Yes
 Surface Mount Compatible (SMC) N/A
 Temperature Range - Operating -35°C to +85°C
 Termination Interface: Style IDT or Pierce
 Wire Size AWG 12

Electrical

Current - Maximum per Contact 20.0A
 Voltage - Maximum 600V

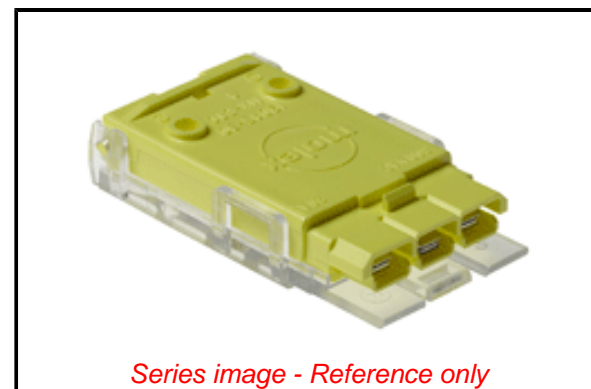

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 ED/108/2014 (17 Dec
 2014)

Halogen-Free

Status

Not Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series

19403 Series

Mates With

19045-1000 Self-Contained Power Connector for Solid Cable, 12-14 AWG,
19403-1010 Self-Contained Power Connector for Stranded Cable, 12 AWG,
19402-1010 Self-Contained Power Tap Connector for Stranded Cable, 12 AWG,
19424-0002 Self-Contained Connector Splitter Assembly

Use With

19045-3180 Safety Cap, 19403-1060 Weather Tight Male Boot for 12-16 AWG Marine Stranded Cable, 19403-1061 Weather Tight Female Boot for 12-16 AWG Marine Stranded Cable

Material Info

Engineering Number

194031010 P

Reference - Drawing Numbers

Product Specification

PS-19902-011-001

Sales Drawing

SD-19045-001-001, SD-19403-110

This document was generated on 07/25/2017

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION