

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0191310004**
Status: **Active**
Overview: Solderless Terminals
Description: InsulKrimp™ Block Spade Tongue Terminal for 10 to 12 AWG Wire, Stud Size 8 (M4), Length 27.31mm

Documents:

[Drawing \(PDF\)](#) [Product Specification PS-19902-013-001 \(PDF\)](#)
[Product Specification PS-19902-009-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#)

Agency Certification

CSA LR18689
 UL E32244

General

Product Family Ring and Spade Terminals
 Series [19131](#)
 Crimp Quality Equipment Yes
 Mil-Spec N/A
 Overview [Solderless Terminals](#)
 Product Name InsulKrimp™
 Type Spade Block
 UPC 800753101272

Physical

Barrel Type Closed
 Color - Resin Natural
 Flammability 94V-0
 Insulation PVC
 Material - Plating Mating Tin
 Net Weight 1.836/g
 Packaging Type Bag
 Plating min - Mating 0.305µm
 Plating min - Termination 0.305µm
 Stud Size 8 (M4)
 Termination Interface: Style Crimp or Compression
 Wire Insulation Diameter 6.40mm max.
 Wire Size AWG 10, 12
 Wire Size mm² 3.30-5.00

Solder Process Data


Lead-freeProcess Capability N/A

Material Info

Engineering Number C-2105-08X

Reference - Drawing Numbers

Product Specification PS-19902-009-001, PS-19902-011-001, PS-19902-013-001
 Sales Drawing CCD20301

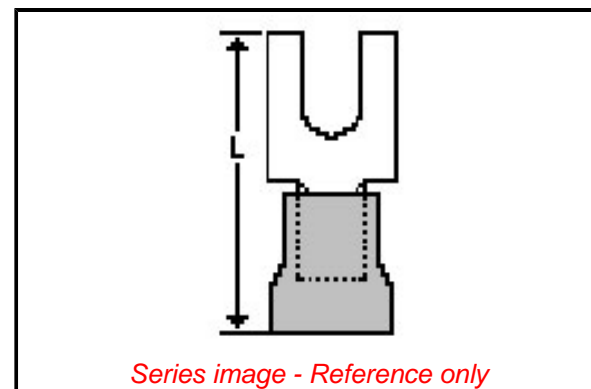

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - ED/30/2017 (7 July 2017)

Halogen-Free

Status

Not Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS Green Image
 ELV Not Relevant
 RoHS Phthalates Not Contained

Search Parts in this Series

[19131 Series](#)